


FPWLCCLCDD

Base Product

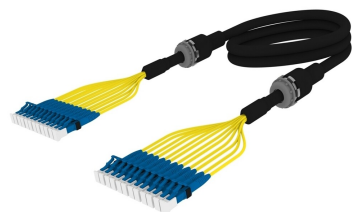

SingleMode LC/UPC to LC/UPC, InstaPATCH® 360 Indoor/Outdoor Armored Ruggedized Fiber Fanout Cable Assembly, 12-Fiber, LSZH/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications


Color, boot A	Blue
Color, connector A	Blue
Color, boot B	Blue
Color, connector B	Blue
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Black
Polarity	Pairs, flipped
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	8 – 999

FPWLCCLCDD

Ordering Tree

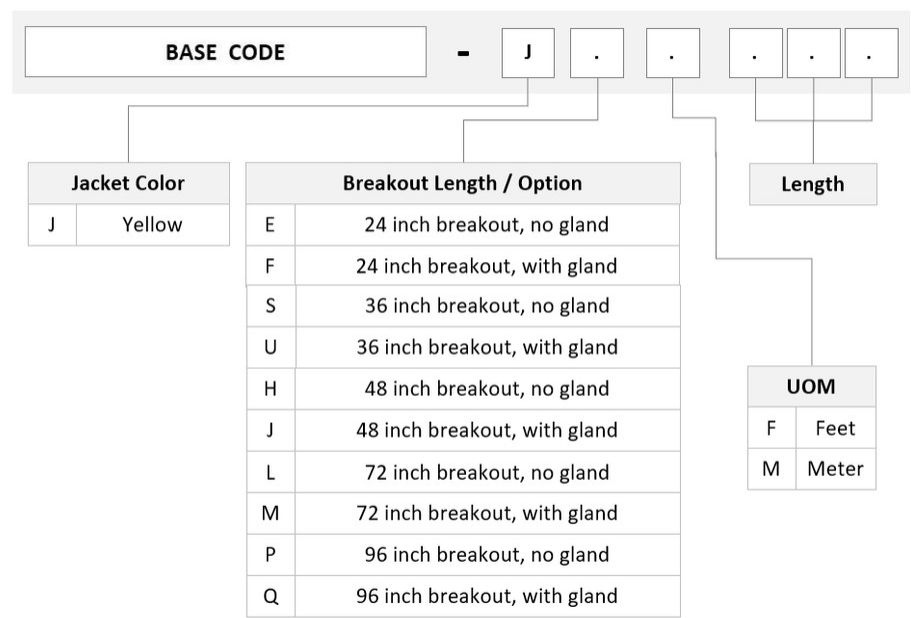

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.652.D | G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Environmental Space Dual Rated LSZH/Riser | Indoor/Outdoor

Packaging and Weights

Packaging quantity 1

Included Products

760164897 Z-012-MZ-8W-F12BK – Fiber indoor/outdoor cable, TeraSPEED® Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored, Singlemode G.652.D and G.657.A1, 24 fiber multi-unit with 12

FPWLCLCDD

860655488	–	fiber subunits, Feet jacket marking, Black jacket color LC/UPC Connector, Singlemode, Blue
-----------	---	---