

FPXLCLCDD

Base Product



OM4 LC/UPC to LC/UPC 12-Fiber InstaPATCH® 360 Indoor/Outdoor Armored Ruggedized Fanout Cable, LSZH/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications


Color, boot A	Aqua
Color, connector A	Black
Color, boot B	Aqua
Color, connector B	Black
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Black
Fibers per Subunit, quantity	12
Total Fibers, quantity	12

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	8 – 999

Ordering Tree

FPXLCLCDD

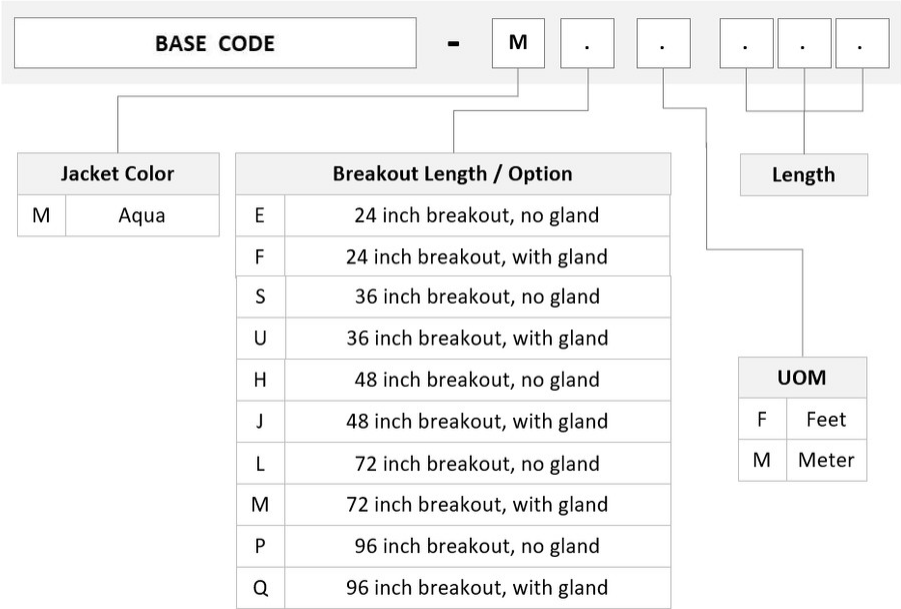

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)
Environmental Space Dual Rated LSZH/Riser | Indoor/Outdoor

Included Products

- 760160077 Z-012-MZ-5K-F12BK – Fiber indoor/outdoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk, interlocking aluminum armored, Multimode OM4, 12 fiber multi-unit with 12 fiber subunits, Gel-free, Feet jacket marking, Black jacket color
- 860637378 – LazrSPEED® Elite LC Connector duplex for 1.6 mm Fiber, multimode