

Copper Cable, Category 6, U/UTP, 23 AWG, CM, Reelspeed, 1000 ft, gray

Product Classification

Regional Availability	Asia Australia/New Zealand
Portfolio	NETCONNECT®
Product Type	Twisted pair cable


General Specifications

ANSI/TIA Category	6
Cable Component Type	Horizontal
Cable Type	U/UTP (unshielded)
Conductor Type, singles	Solid
Conductors, quantity	8
Jacket Color	Gray
Pairs, quantity	4
Transmission Standards	ANSI/TIA-568.2-D ISO/IEC 11801 Class E

Dimensions

Cable Length	304.8 m 1000 ft
Diameter Over Jacket, nominal	6.401 mm 0.252 in
Conductor Gauge, singles	23 AWG

Cross Section Drawing

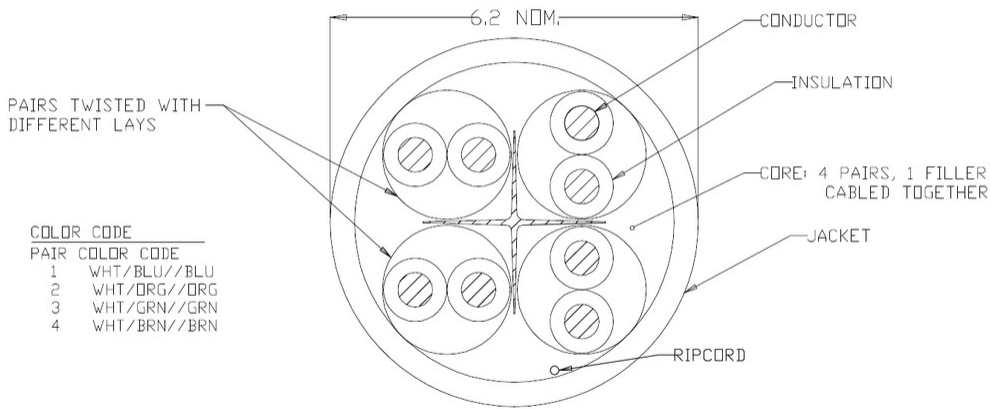

Electrical Specifications

Nominal Velocity of Propagation (NVP)	69 %
Operating Voltage, maximum	80 V
Remote Powering	Fully complies with the recommendations set forth by IEEE 802.3bt (Type 4) for the safe delivery of power over LAN cable when installed according to ISO/IEC 14763-2, CENELEC EN 50174-1, CENELEC EN 50174-2 or TIA TSB-184-A

Material Specifications

Conductor Material	Bare copper
Jacket Material	PVC

Environmental Specifications

Flame Test Method	CM IEC 60332-1
--------------------------	------------------

Packaging and Weights

Packaging Type	Reel
-----------------------	------

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

64991030-01A | 64991030-01A

UK-ROHS

Compliant

