


FibrBoss Wall Mounting Fiber Optic Box, outdoor, 6 LC/APC adapters, with pre-installed pigtails

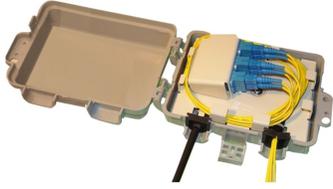

- Intended as a small patch and splice or fiber “hands-off” enclosure
- Environmentally secure housing for indoor or outdoor wall mounted application
- Accommodates field supplied flat or round drop cable inputs
- Cable retention brackets are integrated into the fiber management tray
- Splice protection sleeves are included to add customer convenience and efficiency

Product Classification

Regional Availability	Asia Australia/New Zealand Latin America North America
Product Type	Fiber wall box
Product Series	PB06

General Specifications

Functionality	Patching Splicing
Access	Front
Application	For cables with outer diameter up to 10 mm: each on both sides
Cable Type	Pigtails - Stranded
Enclosure Color	Beige
Front Cover Type	Hinged with lock
Interface	LC/APC
Lock Type	Padlock ready
Mounting	Pedestal Pole Wall
Port, quantity	6
Splicing Capacity, maximum	6

Dimensions

Height	121.92 mm 4.8 in
Width	162.56 mm 6.4 in
Depth	60.96 mm 2.4 in

Ordering Tree

F - PB06 - BC2 - R _ _ _ - _ _ _ - _ _ _ - 0 _ _

Pigtail Count

N	N	No pigtails
0	2	Two pigtails
0	4	Four pigtails
0	6	Six pigtails

Connector Type

N	N	None
S	1	SC/UPC
S	2	SC/APC
L	1	LC/UPC (Limited to 6 pigtails total)
L	2	LC/APC (Limited to 6 pigtails total)

Pigtail Fiber/Cable Type (Singlemode)

N	No pigtails
A	900um Buffer, Color Coded (Internal Pigtails Only)

Pigtail Packaging

N	No Adapters, No Pigtails
2	Adapters and Internal Pigtails Included and Installed
5	Adapters Included and Installed, No Pigtails

Number of Adapters (and pigtails if selected)

0	0	No pigtails
0	1	One-Meter Pigtails

Material Specifications

Enclosure Material Type LSZH thermoplastic

Optical Specifications

Fiber Mode Singlemode

Insertion Loss, Terminal Connector, maximum 0.2 dB

Return Loss, Connector, minimum 55 dB

Environmental Specifications

Environmental Space Outdoor

Flammability Rating UL 94 V-0

Qualification Standards IEC 60529, IP65

Packaging and Weights

Included Splice protectors | Splice tray

Packaging quantity 1

Packaging Type Box | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

