


# CK7755-000 | FIST-GPST-12-NAL2-2

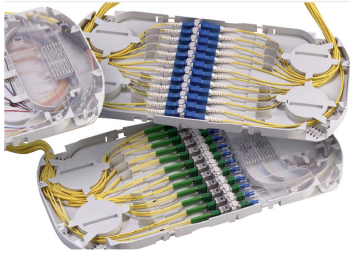

FIST GPST Fiber Patch/Splice Tray, 24 ports, LC/APC, singlemode, ANT splice chip, 19 in, gray, left patch cord routing

## Product Classification

|                              |                         |
|------------------------------|-------------------------|
| <b>Regional Availability</b> | EMEA                    |
| <b>Product Type</b>          | Fiber patch/splice tray |
| <b>Product Brand</b>         | FIST®                   |
| <b>Product Series</b>        | FIST-GPST               |

## General Specifications

|                                  |                          |
|----------------------------------|--------------------------|
| <b>Functionality</b>             | Patching   Splicing      |
| <b>Color</b>                     | Gray                     |
| <b>Interface, front</b>          | LC/APC                   |
| <b>Patch Cord Entry Location</b> | Front, left side         |
| <b>Splicing Type</b>             | ANT, single fiber fusion |
| <b>Total Ports, quantity</b>     | 24                       |

## Dimensions

|               |                    |
|---------------|--------------------|
| <b>Height</b> | 18 mm   0.709 in   |
| <b>Width</b>  | 355 mm   13.976 in |
| <b>Depth</b>  | 190 mm   7.48 in   |

## Optical Specifications

|                   |            |
|-------------------|------------|
| <b>Fiber Mode</b> | Singlemode |
|-------------------|------------|

## Environmental Specifications

|                              |                                      |
|------------------------------|--------------------------------------|
| <b>Operating Temperature</b> | -5 °C to +45 °C (+23 °F to +113 °F)  |
| <b>Storage Temperature</b>   | -30 °C to +60 °C (-22 °F to +140 °F) |

# CK7755-000 | FIST-GPST-12-NAL2-2

---

**Relative Humidity** Up to 93%, non-condensing

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Below maximum concentration value  |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant  |
| UK-ROHS       | Compliant  |

