


# CZ1123-000 | FDC-B8-2-S1/8-0-NN-A -INT01

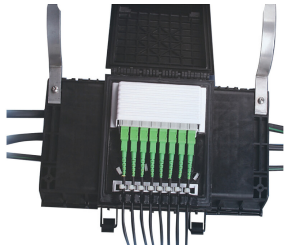

FDC Fiber Optic Splice/Patch Closure, Gel Cable Sealing, 8 SC/UPC Adapters, 48 fusion splices

## Product Classification

<b>Regional Availability</b>	Asia   Latin America
<b>Product Type</b>	In-line, rectangular fiber closure
<b>Product Series</b>	FDC

## General Specifications

<b>Cable Ports Quantity, total</b>	14 round ports
<b>Cable Sealing Type</b>	Compressed gel
<b>Closure Sealing Type</b>	Hinged with latch
<b>Closure Style</b>	In-line
<b>Color</b>	Black
<b>Mounting</b>	Manhole   Pedestal   Strand   Wall
<b>Port Type</b>	SC/UPC
<b>Port, quantity</b>	8
<b>Splice Tray Included, quantity</b>	2
<b>Splice Tray Type Included</b>	24-way, heat shrink
<b>Splitter Type</b>	No splitter
<b>Splitter, quantity</b>	0

## Dimensions

<b>Height</b>	133 mm   5.236 in
<b>Width</b>	34 mm   1.339 in
<b>Length</b>	167 mm   6.575 in

## Material Specifications

<b>Material Type</b>	Rugged polymer
----------------------	----------------

## Environmental Specifications

**Environmental Space**                      Above ground | Below ground

## Packaging and Weights

**Packaging quantity**                      1

**Packaging Type**                      Box | Carton

## Regulatory Compliance/Certifications

### Agency

### Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

ROHS

Compliant

UK-ROHS

Compliant

