


F56475-000 | FIST-GPST-12-AAE5E-2

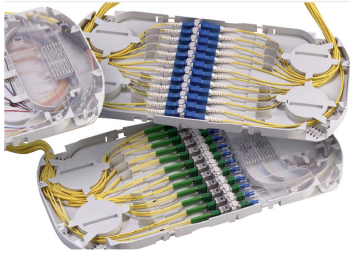

FIST GPST Fiber Patch Tray, 12 ports, LSH/UPC, multimode, 19 in, gray , left/right patch cord routing

Product Classification

| | |
|------------------------------|------------------|
| Regional Availability | EMEA |
| Product Type | Fiber patch tray |
| Product Brand | FIST® |
| Product Series | FIST-GPST |

General Specifications

| | |
|-----------------------------------|--------------------------------------|
| Functionality | Patching |
| Color | Gray |
| Interface, front | LSH/UPC |
| Patch Cord Entry Location | Front, left side Front, right side |
| Patching Capacity, maximum | 12 |
| Splicing Capacity, maximum | 0 |
| Total Ports, quantity | 12 |

Dimensions

| | |
|---------------|--------------------|
| Height | 18 mm 0.709 in |
| Width | 355 mm 13.976 in |
| Depth | 190 mm 7.48 in |

Optical Specifications

| | |
|-------------------|-----------|
| Fiber Mode | Multimode |
|-------------------|-----------|

Environmental Specifications

| | |
|------------------------------|-------------------------------------|
| Operating Temperature | -5 °C to +45 °C (+23 °F to +113 °F) |
|------------------------------|-------------------------------------|

F56475-000 | FIST-GPST-12-AAE5E-2

Storage Temperature -30 °C to +60 °C (-22 °F to +140 °F)

Relative Humidity Up to 93%, non-condensing

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

