


FPS-SPA1EJJ

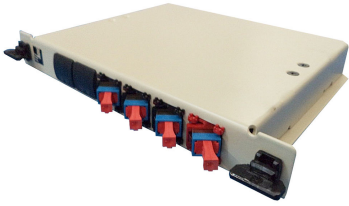

FCM/FL2 VAM Fiber Optic Splitter Module, 2 x 32, standard, SC/APC, singlemode

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Splitter module
Product Series	FDF

General Specifications

Device Type	Standard VAM
Functionality	Splitting
Access	Rear
Application	For use with FDF frames For use with FL2 panels
Circuits, quantity	1
Distribution Type	2 x 32 splitter
Interface, front	SC/APC
Interface, Input	SC/APC
Interface, Output	SC/APC
Interface, rear	SC/APC
Module Color	Putty white
Split Ratio	Symmetrical
Splitter, quantity	1

Optical Specifications

Directivity, minimum	55 dB
Polarization Dependent Loss, maximum	0.4 dB
Uniformity, maximum	2 dB

FPS-SPA1EJJ

Insertion Loss, Splitter, maximum	17.4 dB
Insertion Loss, Splitter, typical	16.2 dB
Return Loss, Splitter, minimum	55 dB

Environmental Specifications

Flammability Rating	UL 94 V-0
----------------------------	-----------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

