

FPX-12MPLS07



FPX Fiber Optic MPO Module, Singlemode OS2, 12 fiber SC/UPC adapter, left, putty white

- FPX modules offer the end-user the flexibility of a plug-and-play MPO architecture with a “grow as you go” approach to the network
- Each module has a front bulkhead identical to the adapter pack with an internal cable assembly converting to an MPO male connector
- All fiber connectivity is housed in an enclosed module with a rear MPO adapter allowing the user to utilize an MPO trunk to turn up service

Product Classification

| | |
|------------------------------|---------------|
| Regional Availability | North America |
| Portfolio | CommScope® |
| Product Type | Fiber module |
| Product Series | FPX |

General Specifications

| | |
|-------------------------------------|----------------------------|
| Functionality | Breakout |
| Application | For use with FPX panels |
| Adapter Color | Blue |
| Adapters, quantity, front | 12 |
| Adapters, quantity, rear | 1 |
| Body Style | Left orientation Simplex |
| Color, front | Putty white |
| Color, housing | Putty white |
| Color, rear | Putty white |
| Interface, front | SC/UPC |
| Interface, rear | MPO |
| Interface Feature, rear | Standard |
| Polarity | Pairs, straight |
| Total Ports, quantity, front | 12 |

Dimensions


| | |
|---------------|-------------------|
| Height | 33.02 mm 1.3 in |
|---------------|-------------------|

FPX-12MPLS07

Width 176.53 mm | 6.95 in

Depth 127 mm | 5 in

Ordering Tree

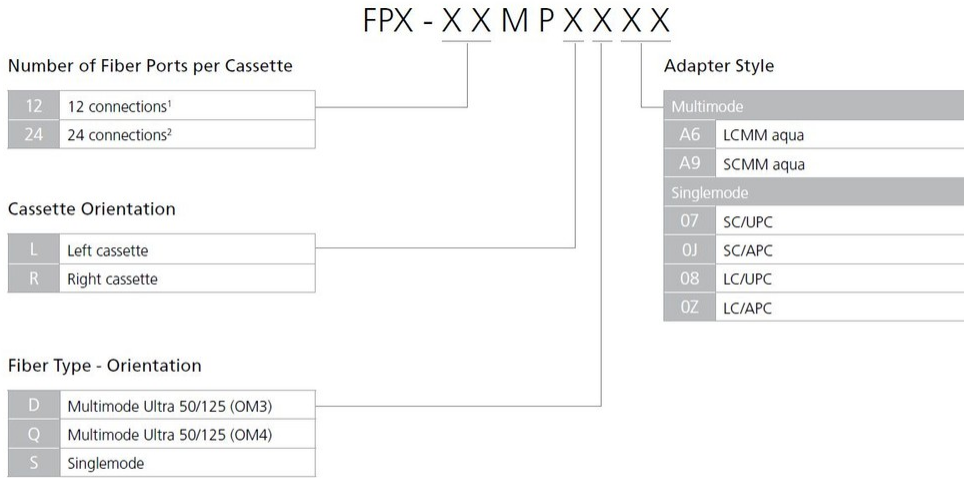

¹ SC only

² LC only

Optical Specifications

Fiber Mode Singlemode

Fiber Type OS2

Environmental Specifications

Operating Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Packaging quantity 1

Packaging Type Bag | Carton

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |

FPX-12MPLS07

| | |
|-------------------|---|
| ROHS | Compliant |
| TL 9000:2016 (R6) | Compliant to this quality management practice |
| UK-ROHS | Compliant |

