


FibrBoss Wall Mounting Fiber Optic Box, outdoor, 6 SC/UPC adapters, with pre-installed pigtails

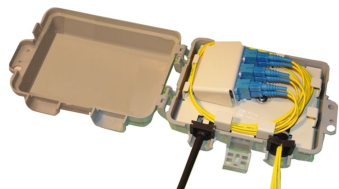

- Intended as a small patch and splice or fiber “hands-off” enclosure
- Environmentally secure housing for indoor or outdoor wall mounted application
- Accommodates field supplied flat or round drop cable inputs
- Cable retention brackets are integrated into the fiber management tray
- Splice protection sleeves are included to add customer convenience and efficiency

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Latin America   North America
<b>Product Type</b>	Fiber wall box
<b>Product Series</b>	PB06

## General Specifications

<b>Functionality</b>	Patching   Splicing
<b>Access</b>	Front
<b>Application</b>	For cables with outer diameter up to 10 mm: each on both sides
<b>Cable Type</b>	Pigtails - Stranded
<b>Enclosure Color</b>	Beige
<b>Front Cover Type</b>	Hinged with lock
<b>Interface</b>	SC/UPC
<b>Lock Type</b>	Padlock ready
<b>Mounting</b>	Pedestal   Pole   Wall
<b>Port, quantity</b>	6
<b>Splicing Capacity, maximum</b>	6

## Dimensions

<b>Height</b>	121.92 mm   4.8 in
<b>Width</b>	162.56 mm   6.4 in
<b>Depth</b>	60.96 mm   2.4 in

## Material Specifications

<b>Enclosure Material Type</b>	LSZH thermoplastic
--------------------------------	--------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Insertion Loss, Terminal Connector, maximum</b>	0.2 dB
<b>Return Loss, Connector, minimum</b>	55 dB

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
<b>Flammability Rating</b>	UL 94 V-0
<b>Qualification Standards</b>	IEC 60529, IP65

## Packaging and Weights

<b>Included</b>	Splice protectors   Splice tray
<b>Packaging quantity</b>	1
<b>Packaging Type</b>	Box   Carton

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

