


1675235 | FD3-AE144J00JBBP1-P

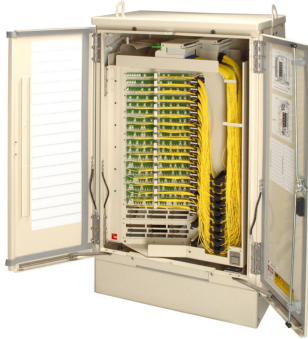

FDH 3000 Small Fiber Distribution Pole Mount Cabinet, 144F, SC /APC, no splitters, dielectric loose tube, 100 ft, 12F

Product Classification

| | |
|------------------------------|------------------------|
| Regional Availability | North America |
| Product Type | Fiber distribution hub |
| Product Series | FDH 3000 |

General Specifications

| | |
|--|-------------------------|
| Access | Front |
| Cable Type | Dielectric - Loose Tube |
| Color | Putty white |
| Distribution Cables, quantity | 1 |
| Distribution Ports, quantity | 288 |
| Fibers per Distribution Cable, quantity | 144 |
| Fibers per Feeder Cable, quantity | 12 |
| Interface, Input | SC |
| Interface Feature, Input | APC |
| Mounting | Pad |
| Splitter Slots, quantity | 12 |

Dimensions

| | |
|-----------------------|------------------|
| Height | 914.4 mm 36 in |
| Width | 685.8 mm 27 in |
| Cable Length | 30.48 m 100 ft |
| Depth | 457.2 mm 18 in |
| Enclosure Size | Small |

Material Specifications

| | |
|----------------------|---------------|
| Finish | Powder coated |
| Material Type | Steel |

Environmental Specifications

| | |
|----------------------------|--------------|
| Environmental Space | Above ground |
|----------------------------|--------------|

Packaging and Weights

| | |
|---------------------------|--------|
| Packaging quantity | 1 |
| Packaging Type | Pallet |

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Above maximum concentration value |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant/Exempted |

