


605352-000 | FIST-GSS2-MA

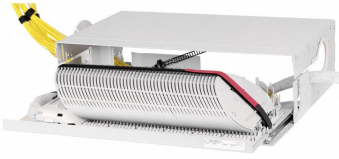

FIST-GSS2 Fiber Splice Panel, 3RU, Etsi, for splicing loose tube cable to pigtail, no trays included, gray

Product Classification

Regional Availability	EMEA
Portfolio	CommScope®
Product Type	Fiber splice panel
Product Brand	FIST®
Product Series	FIST-GSS2

General Specifications

Functionality	Splicing
Application	Compatible with FIST-GR3-style frames
Cable Exit Location	Rear, right side
Cable Stub Type	Indoor/outdoor, stranded
Color	Gray
Interface, front	Unloaded
Patch Cord Routing	Left sided
Rack Type	ETSI 600 mm FIST-GR3
Rack Units	3
Shelf Movement	Sliding
Splice Trays Included, quantity	0

Dimensions

Height	133.35 mm 5.25 in
Width	531 mm 20.906 in

Material Specifications

Finish	Powder coated
Material Type	Galvanized steel

605352-000 | FIST-GSS2-MA

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity	Up to 93%, non-condensing

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

