


FD3-MM288J00000FOC

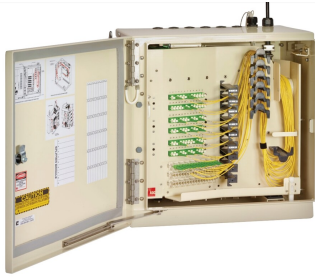

IFDH 3000 Indoor Fiber Distribution Hub, 288 fiber, SC/APC, ribbon pigtails, spliced input, 48f feeder

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	IFDH 3000

General Specifications

Functionality	Patching Splicing
Access	Front
Adapters, quantity	288
Cable Type	Pigtails - Ribbon
Color	Putty white
Distribution Cables, quantity	24
Fibers per Distribution Cable, quantity	12
Fibers per Feeder Cable, quantity	48
Front Door Type	Single hinged
Interface	SC/APC
Mounting	Wall
Port, quantity	288
Splitter Slots, quantity	18

Dimensions

Height	839 mm 33.032 in
Width	600 mm 23.622 in
Depth	427 mm 16.811 in
Enclosure Size	Medium

Material Specifications

FD3-MM288J00000FOC

Finish Powder coated

Material Type Aluminum

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Environmental Space Indoor

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

