


# FD3-MM288J00V00EOC

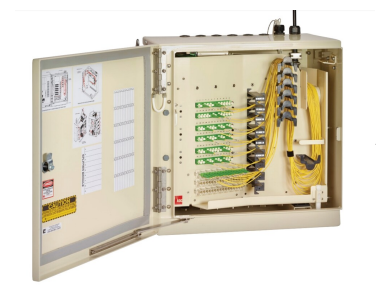

IFDH 3000 Indoor Fiber Distribution Hub, 288F, SC/APC, loose tube /stranded pigtails, spliced input/dist., 48FF

## Product Classification

|                       |                        |
|-----------------------|------------------------|
| Regional Availability | North America          |
| Product Type          | Fiber distribution hub |
| Product Series        | IFDH 3000              |

## General Specifications

|   |                     |
|---|---------------------|
| Functionality                           | Patching   Splicing |
| Access                                  | Front               |
| Adapters, quantity                      | 288                 |
| Cable Type                              | Pigtails - Stranded |
| Color                                   | Putty white         |
| Distribution Cables, quantity           | 24                  |
| Fibers per Distribution Cable, quantity | 12                  |
| Fibers per Feeder Cable, quantity       | 48                  |
| Front Door Type                         | Single hinged       |
| Interface                               | SC/APC              |
| Mounting                                | Wall                |
| Port, quantity                          | 288                 |
| Splitter Slots, quantity                | 18                  |

## Dimensions

|                |                    |
|----------------|--------------------|
| Height         | 736.6 mm   29 in   |
| Width          | 533.4 mm   21 in   |
| Depth          | 368.3 mm   14.5 in |
| Cable Length   | 30.48 m   100 ft   |
| Enclosure Size | Medium             |

# FD3-MM288J00V00EOC

---

## Material Specifications

|               |               |
|---------------|---------------|
| Finish        | Powder coated |
| Material Type | Aluminum      |

## Optical Specifications

|            |            |
|------------|------------|
| Fiber Mode | Singlemode |
|------------|------------|

## Environmental Specifications

|                     |        |
|---------------------|--------|
| Environmental Space | Indoor |
|---------------------|--------|

## Packaging and Weights

|                    |   |
|--------------------|---|
| Packaging quantity | 1 |
|--------------------|---|

## Regulatory Compliance/Certifications

| Agency     | Classification  |
|------------|---|
| CHINA-ROHS | Above maximum concentration value   |
| REACH-SVHC | Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS       | Compliant/Exempted  |
| UK-ROHS    | Compliant/Exempted  |

