


NG4-MMD7E0R000

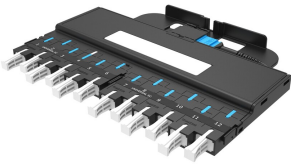

NG4access® MPO Module, singlemode, SC/UPC-MPO 12 fiber, right exit
(for MPO module)

- Offers the same craft-friendly interface for LC and SC connectors as the cabled module
- Allow installers to connect an MPO trunk cable to turn up services in rapid installation applications

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	NG4access®
Product Series	NG4

General Specifications

Functionality	Breakout
Application	NG4 MPO module
Adapter Color	Blue
Adapters, quantity, front	12
Body Style	Simplex
Color, front	Black
Color, housing	Black
Color, rear	Black
Interface, front	SC/UPC
Interface, rear	MPO
Interface Feature, rear	Standard
Polarity	Method A
Total Fibers, quantity	12
Total Ports, quantity, front	12

Dimensions

Height	13.21 mm 0.52 in
Width	159.77 mm 6.29 in

NG4-MMD7E0R000

Depth 130.3 mm | 5.13 in

Outline Drawing



Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2

Environmental Specifications

Operating Temperature -5 °C to +40 °C (+23 °F to +104 °F)
Storage Temperature -5 °C to +50 °C (+23 °F to +122 °F)
Relative Humidity Up to 85%, non-condensing

Packaging and Weights

Packaging quantity 1
Packaging Type Bag | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

NG4-MMD7E0R000

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted

