


760237957 | EHD08-DM-24LC-SM-B-ULL

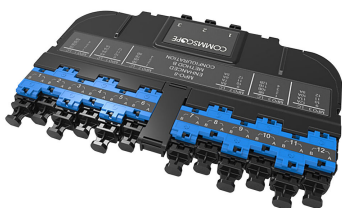

EHD ULL Singlemode MPO-8 distribution module, 24LC to 3x8f MPOs unpinned, dust plugs

This product will be discontinued on: June 30, 2026

Replaced By:

760252339 Propel ULL Singlemode MPO-08 Distribution Module, 12 duplex LC/UPC to 3X8f MPO/APC non-pinned, Method B Enhanced
PPL-DM-8AU-24LC-SM-BEU

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	SYSTIMAX ULL
Product Series	EHD

General Specifications

Functionality	Breakout
Color, front	Blue
Color, rear	Gray
Interface, front	LC/UPC
Interface, rear	MPO
Interface Feature, rear	Key up/up MPO Non-Pinned
Polarity	Method B Enhanced (ULL)
Shuttered	No
Total Fibers, quantity	24

Dimensions

Height	12.45 mm 0.49 in
--------	--------------------

Width	169.67 mm 6.68 in
Depth	115.32 mm 4.54 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum	0.6 dB

Environmental Specifications

Qualification Standards	IEC 61753-1 TIA-604-3-B
Safety Standard	CE CSA UL

Packaging and Weights

Packaging quantity	1
Weight, net	0.136 kg 0.3 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

