


760237993 | EHD12-DM-24LC-LS-B-ULL

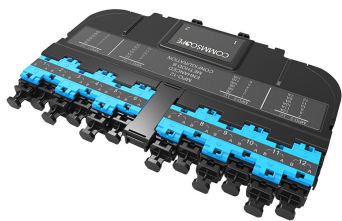

EHD ULL Multimode OM4 MPO-12 distribution module, 24LC to 2x12f MPOs unpinned, dust plugs

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	SYSTIMAX ULL
Product Series	EHD

General Specifications

Functionality	Breakout
Color, front	Aqua
Color, rear	Gray
Interface, front	LC/UPC
Interface, rear	MPO
Interface Feature, rear	Key up/up MPO Non-Pinned
Polarity	Method B Enhanced (ULL)
Shuttered	No
Total Fibers, quantity	24

Dimensions

Height	12.45 mm 0.49 in
Width	169.67 mm 6.68 in
Depth	115.32 mm 4.54 in

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

760237993 | EHD12-DM-24LC-LS-B-ULL

Fiber Type OM4 | OM4, LazrSPEED® 550
Insertion Loss, maximum 0.35 dB

Environmental Specifications

Qualification Standards IEC 61753-1 | TIA-568.3-D
Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1
Weight, net 0.136 kg | 0.3 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

