


760109512 | 360G2 Cassette 6-SC-LS-AQ-Pigtails A

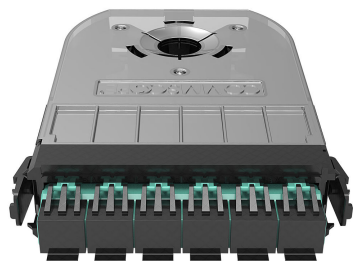

360G2 Cassette 6 SC Multimode Aqua with Pigtails A

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails

General Specifications

Adapter Color	Aqua
Interface Feature, front	Standard
Interface, front	SC
Total Fibers, quantity	6
Total Ports, quantity, front	6

Dimensions

Height	30.48 mm 1.2 in
Width	91.44 mm 3.6 in
Pigtail Length	1.5 m 4.921 ft
Depth	119.38 mm 4.7 in

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
Insertion Loss, typical	0.4 dB
Return Loss, minimum	20 dB

Environmental Specifications

Safety Standard	UL
------------------------	----

760109512 | 360G2 Cassette 6-SC-LS-AQ-Pigtails A

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance



Included Products

700207012
MFA-SC06-AQ-SHUTTERED — LazrSPEED® SC Multiport Shuttered Adapter, Aqua, Single Pack

- 860278738 — LazrSPEED® 550 SC 0.9 mm Pigtail, blue, 1.5 m
- 860278746 — LazrSPEED® 550 SC 0.9 mm Pigtail, orange, 1.5 m
- 860278753 — LazrSPEED® 550 SC 0.9 mm Pigtail, green, 1.5 m
- 860278761 — LazrSPEED® 550 SC 0.9 mm Pigtail, brown, 1.5 m
- 860278779 — LazrSPEED® 550 SC 0.9 mm Pigtail, slate, 1.5 m
- 860278787 — LazrSPEED® 550 SC 0.9 mm Pigtail, white, 1.5 m

700207012 | MFA-SC06-AQ-SHUTTERED

LazrSPEED® SC Multiport Shuttered Adapter, Aqua, Single Pack

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter
Product Brand	LazrSPEED®
Product Series	MFA

General Specifications

Body Style	Ganged
Color	Aqua
Interface	SC
Interface Feature	Standard
Mounting	No flange
Shuttered	Yes
Total Ports, quantity	6

Material Specifications

Alignment Sleeve Material	Zirconia (ceramic)
----------------------------------	--------------------

Optical Specifications

Fiber Mode	Multimode
-------------------	-----------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

700207012 | MFA-SC06-AQ-SHUTTERED

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS



Classification


Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

LazrSPEED® 550 SC 0.9 mm Pigtail, blue, 1.5 m

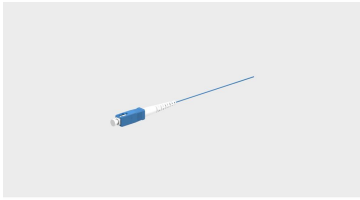

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	Blue
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860278738



LazrSPEED® 550 SC 0.9 mm Pigtail, orange, 1.5 m



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	Orange
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860278746



LazrSPEED® 550 SC 0.9 mm Pigtail, green, 1.5 m

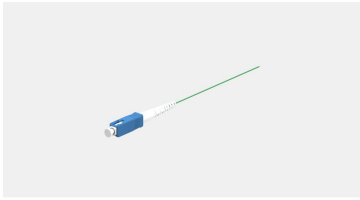

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	Green
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860278753



LazrSPEED® 550 SC 0.9 mm Pigtail, brown, 1.5 m

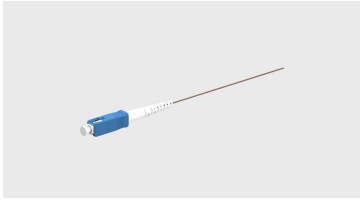

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	Brown
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860278761



LazrSPEED® 550 SC 0.9 mm Pigtail, slate, 1.5 m

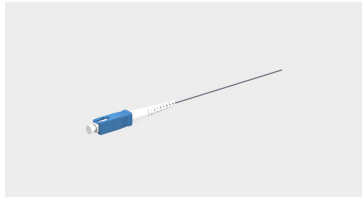

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	Slate
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications


Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



LazrSPEED® 550 SC 0.9 mm Pigtail, white, 1.5 m

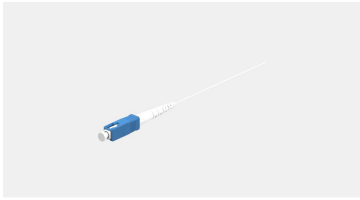

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	LazrSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/UPC
Jacket Color	White
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	OM4, LazrSPEED® 550
-------------------	---------------------

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860278787

