


760109587 | 360G2 Cassette 6-SCA-SM-GR- Pigtails B

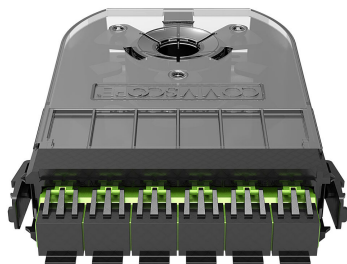

360G2 Cassette 6 SC Angled Singlemode Green with Pigtails B

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails

General Specifications

Adapter Color	Green
Interface Feature, front	Standard
Interface, front	SC
Total Fibers, quantity	6
Total Ports, quantity, front	6

Dimensions

Height	30.48 mm 1.2 in
Width	91.44 mm 3.6 in
Pigtail Length	1.5 m 4.921 ft
Depth	119.38 mm 4.7 in

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
Insertion Loss, typical	0.4 dB
Return Loss, minimum	65 dB

Environmental Specifications

Safety Standard	UL
------------------------	----

760109587 | 360G2 Cassette 6-SCA-SM-GR-Pigtails B

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant



Included Products

- 760061374
AFA-SC06-GR-SHUTTERED — TeraSPEED® SC-APC Multiport Shuttered Adapter, Green, Single Pack
- 860312933 — TeraSPEED® SC APC 0.9 mm Pigtail, red, 1.5 m
- 860312941 — TeraSPEED® SC APC 0.9 mm Pigtail, black, 1.5 m
- 860312958 — TeraSPEED® SC APC 0.9 mm Pigtail, yellow, 1.5 m
- 860312966 — TeraSPEED® SC APC 0.9 mm Pigtail, violet, 1.5 m
- 860312974 — TeraSPEED® SC APC 0.9 mm Pigtail, rose, 1.5 m
- 860312982 — TeraSPEED® SC APC 0.9 mm Pigtail, aqua, 1.5 m

TeraSPEED® SC-APC Multiport Shuttered Adapter, Green, Single Pack

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter
Product Brand	TeraSPEED®
Product Series	AFA

General Specifications

Body Style	Ganged
Color	Green
Interface	SC
Interface Feature	APC
Mounting	No flange
Shuttered	Yes
Total Ports, quantity	6

Material Specifications

Alignment Sleeve Material	Zirconia
----------------------------------	----------

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

760061374 | AFA-SC06-GR-SHUTTERED

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS



Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

TeraSPEED® SC APC 0.9 mm Pigtail, red, 1.5 m



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Red
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312933



TeraSPEED® SC APC 0.9 mm Pigtail, black, 1.5 m



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Black
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312941



TeraSPEED® SC APC 0.9 mm Pigtail, yellow, 1.5 m

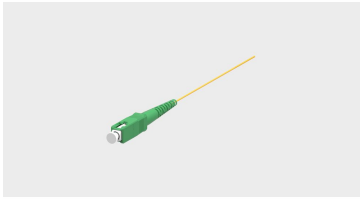

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum


Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312958



TeraSPEED® SC APC 0.9 mm Pigtail, violet, 1.5 m

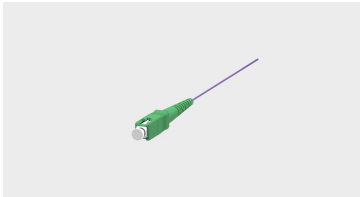

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Violet
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312966



TeraSPEED® SC APC 0.9 mm Pigtail, rose, 1.5 m



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Rose
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312974



TeraSPEED® SC APC 0.9 mm Pigtail, aqua, 1.5 m



Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, simplex
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Aqua
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1 , TeraSPEED® OS2
-------------------	---

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312982

