


760242401 | ODF-FF19CM-36

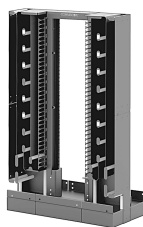

Rack with cable managers, 19" standard mouting, 36ru of open rack space

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Product Type	Frame
Product Series	Flex Frame

General Specifications

Access	Front Rear
Application	For use with any 19" rack mount panels
Color	Black
Growth Configuration	Unloaded
Mounting	Concrete floor Raised floor

Dimensions

Height	2,133.6 mm 84 in
Width	1,339.09 mm 52.72 in
Depth	609.6 mm 24 in

Material Specifications

Finish	Powder coated
Material Type	Steel

Environmental Specifications

Environmental Space	Indoor
Qualification Standards	Telcordia GR-63 Zone 4 Seismic

Packaging and Weights

Included	Cable management
Packaging quantity	1

Packaging Type Crate | Pallet
Weight, net 181.437 kg | 400 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

