

760237706 | FOSC-OPGW-A4NT-0-NNN



FOSC® OPGW A Fiber Optic Splice Closure, Heat Shrink Cable sealing, butt type, no pre-installed trays

Product Classification

Regional Availability

Asia | EMEA | Latin America | North America

Product Type

Single-ended, round fiber closure

Product Brand

FOSC®

Product Series

FOSC OPGW

General Specifications

Cable Entry Drop Port Style

Round

Cable Entry Main Port Style

Round

Cable Ports Quantity, total

1 oval port (2 cables) + 4 round ports

Cable Sealing Type

Heat shrink

Closure Sealing Type

Dome-to-base clamp with O-ring

Closure Style

Single-ended

Color

Black

Ground Feed-through

None

Mounting

Pole | Strand | Wall

Network Area Type

Feeder

Splice Tray Included, quantity

0

Splice Tray Type Included

No trays

Splicing Capacity, Single Fusion, maximum

48

Splicing Capacity, Single Splice, 12 fibers, maximum

48

Splicing Capacity, Single Splice, 6 fibers, maximum

24

Splicing Type, Supported

Mass fusion | Single fusion

Dimensions

Height

240 mm | 9.449 in


Width

202 mm | 7.953 in

760237706 | FOSC-OPGW-A4NT-0-NNN

Length 730 mm | 28.74 in
Main Cable Diameter, maximum 19 mm | 0.748 in

Ordering Tree

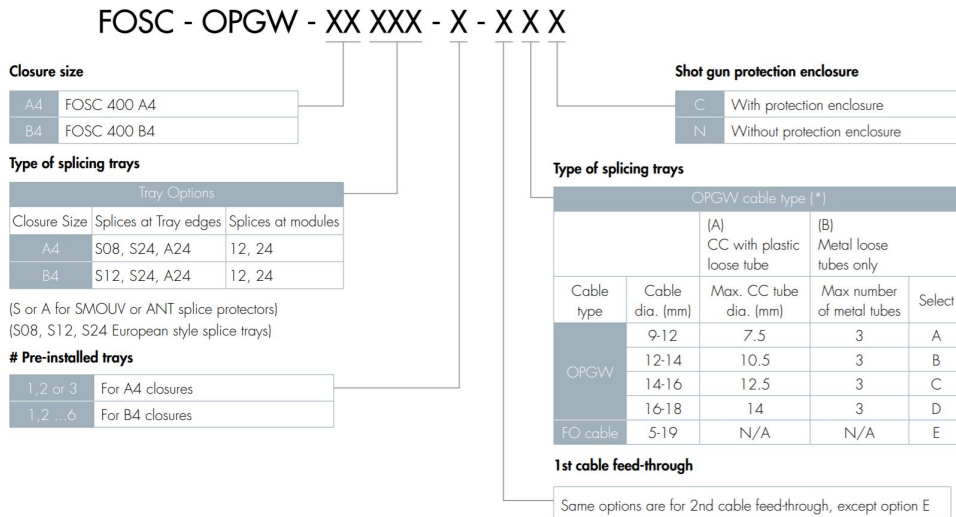

Material Specifications

Material Type Impact-resistant polymer

Environmental Specifications

Environmental Space Above ground
Qualification Standards IEC 61300, 6 m waterhead

Packaging and Weights

Packaging quantity 1
Packaging Type Box | Carton
Weight, net 18 kg | 39.683 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant
UK-ROHS	Compliant

