

760237708 | FOSC-OPGW-B4NT-0/6-NNN



FOSC® OPGW B Fiber Optic Splice Closure, Heat Shrink Cable sealing, butt type, no pre-installed trays

Product Classification

Regional Availability

Asia | EMEA | Latin America | North America

Product Type

Single-ended, round fiber closure

Product Brand

FOSC®

Product Series

FOSC OPGW

General Specifications

Cable Entry Drop Port Style

Round

Cable Entry Main Port Style

Round

Cable Ports Quantity, total

1 oval port (2 cables) + 4 round ports

Cable Sealing Type

Heat shrink

Closure Sealing Type

Dome-to-base clamp with O-ring

Closure Style

Single-ended

Color

Black

Mounting

Pole | Strand | Wall

Network Area Type

Feeder

Splice Tray Included, quantity

0

Splicing Capacity, Mass Fusion, maximum

144

Splicing Capacity, Single Fusion, maximum

96

Splicing Capacity, Single Splice, 12 fibers, maximum

96

Splicing Capacity, Single Splice, 6 fibers, maximum

48

Splicing Type, Supported

Mass fusion | Single fusion

Dimensions

Height


240 mm | 9.449 in

760237708 | FOSC-OPGW-B4NT-0/6-NNN

Width	202 mm 7.953 in
Length	730 mm 28.74 in
Main Cable Diameter, maximum	19 mm 0.748 in

Ordering Tree

FOSC - OPGW - XX XXX - X - X X X

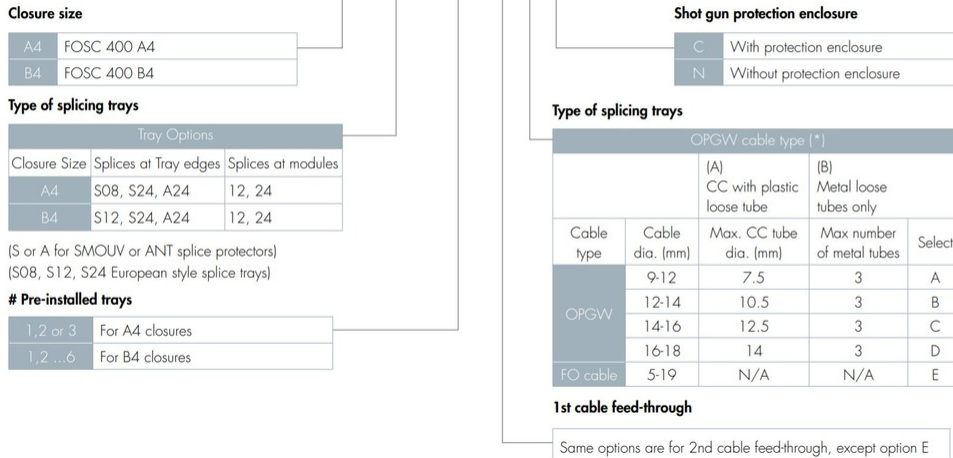

Material Specifications

Material Type	Impact-resistant polymer
----------------------	--------------------------

Environmental Specifications

Environmental Space	Above ground
Qualification Standards	IEC 61300, 6 m waterhead

Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton
Weight, net	18 kg 39.683 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant

