


760238933 | EHD-SP-24LA-SMR-AS

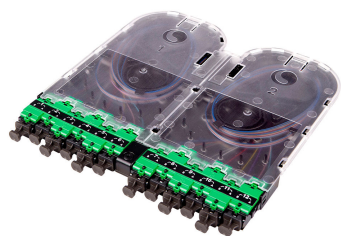

EHD Singlemode Splice Cassette, 24LC/APC with dust plugs and ribbon pigtails

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with ribbon pigtail
Product Series	EHD

General Specifications

Color, front	Green
Interface, front	LC/APC
Interface, rear	Ribbon pigtail
Polarity	Method A Pairs, straight
Shuttered	No
Total Fibers, quantity	24

Dimensions

Height	11.43 mm 0.45 in
Width	169.672 mm 6.68 in
Depth	163.83 mm 6.45 in

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2
Insertion Loss, maximum	0.4 dB

Environmental Specifications

760238933 | EHD-SP-24LA-SMR-AS

Qualification Standards IEC 61753-1 | TIA-568.3-D

Safety Standard CE | CSA | UL

Packaging and Weights

Included Mass Fusion Splice Protection Sleeves

Packaging quantity 1

Weight, net 0.181 kg | 0.4 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

- FST-ACC006 – Fiber Optic Protective Splice Sleeve, 12f mass fusion, 5 pack