


760242108 | PNL-CS-12LCV-PT

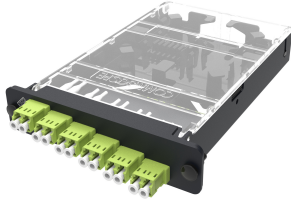

Standard Density (SD) Splicing cassette 12LC OM5, 900#m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber cassette with pigtails

General Specifications

Adapter Color	Lime green
Interface, front	LC/UPC
Interface, rear	Stranded pigtail
Total Fibers, quantity	12
Total Ports, quantity, front	6

Dimensions

Height	28.956 mm 1.14 in
Width	104.648 mm 4.12 in
Depth	165.354 mm 6.51 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM5, LazrSPEED® wideband
Insertion Loss, typical	0.3 dB

Environmental Specifications

Safety Standard	UL
------------------------	----

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system