


FL2-C770024PW-2D00

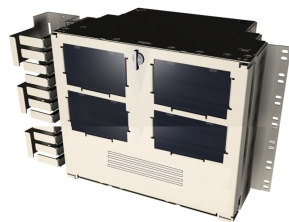

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 24 SC/UPC, singlemode, 8RU, 23 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	4
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Growth Configuration	Partially loaded
Interface, front	SC/UPC
Rack Type	EIA 23 in
Rack Units	8
Shelf Movement	Hinged
Splicing Capacity, maximum	72
Total Ports, quantity	24

Dimensions

Height	355.6 mm 14 in
Width	584.2 mm 23 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-C770024PW-2D00

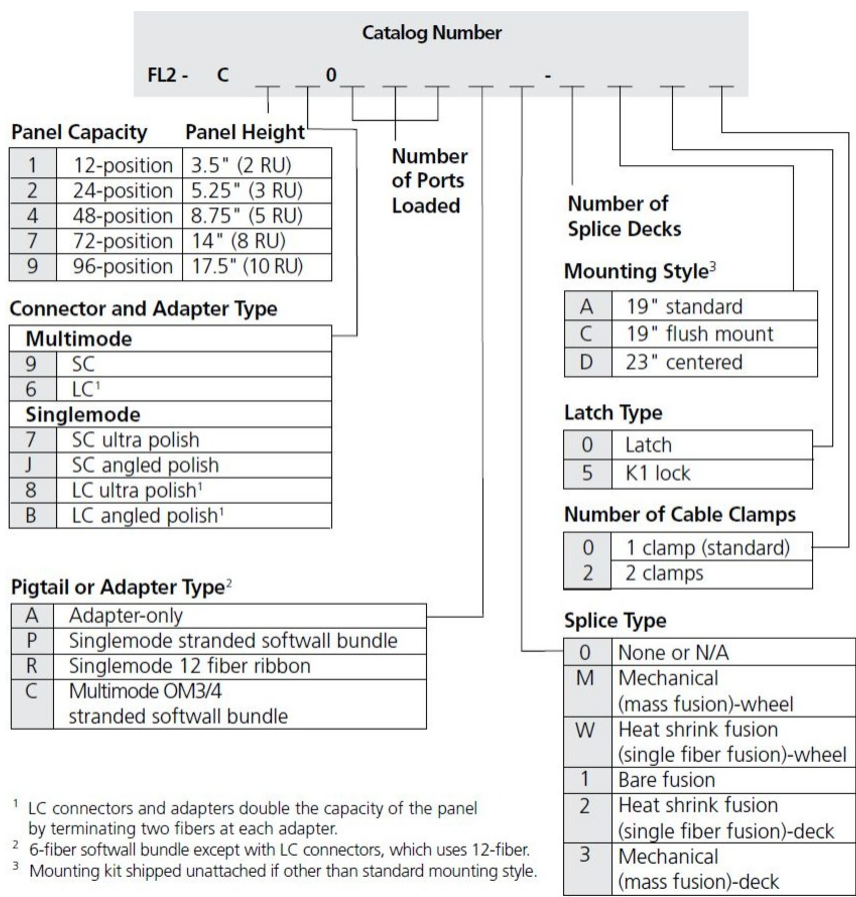

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-C770024PW-2D00

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

