


FL2-CEB0144PN-6A00

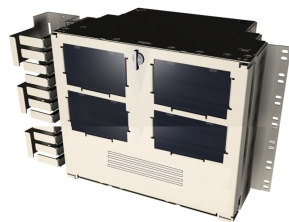

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 144 LC/APC, singlemode, 8RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	12
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	LC/APC
Rack Type	EIA 19 in
Rack Units	8
Shelf Movement	Hinged
Splicing Capacity, maximum	144
Total Ports, quantity	144

Dimensions

Height	355.6 mm 14 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-CEB0144PN-6A00

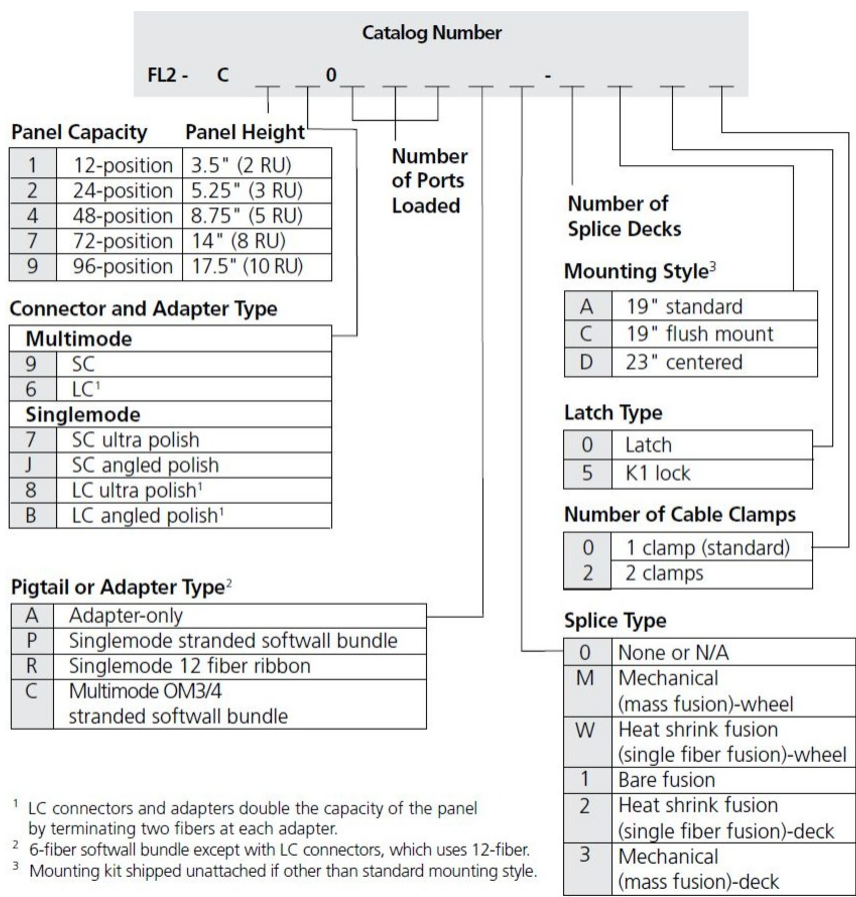

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-CEB0144PN-6A00

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

