

# FL2-R170012A0-0A00



FL2000 Fiber Termination Panel, 12 SC/UPC, singlemode, 1RU, 19 in, putty white

## Product Classification

Regional Availability	Latin America   North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

## General Specifications


Functionality	Patching
Adapter Packs Included, quantity	2
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Rack Type	EIA 19 in
Rack Units	1
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	12

## Dimensions

Height	44.45 mm   1.75 in
Width	482.6 mm   19 in
Depth	257 mm   10.118 in

## Ordering Tree

# FL2-R170012A0-0A00

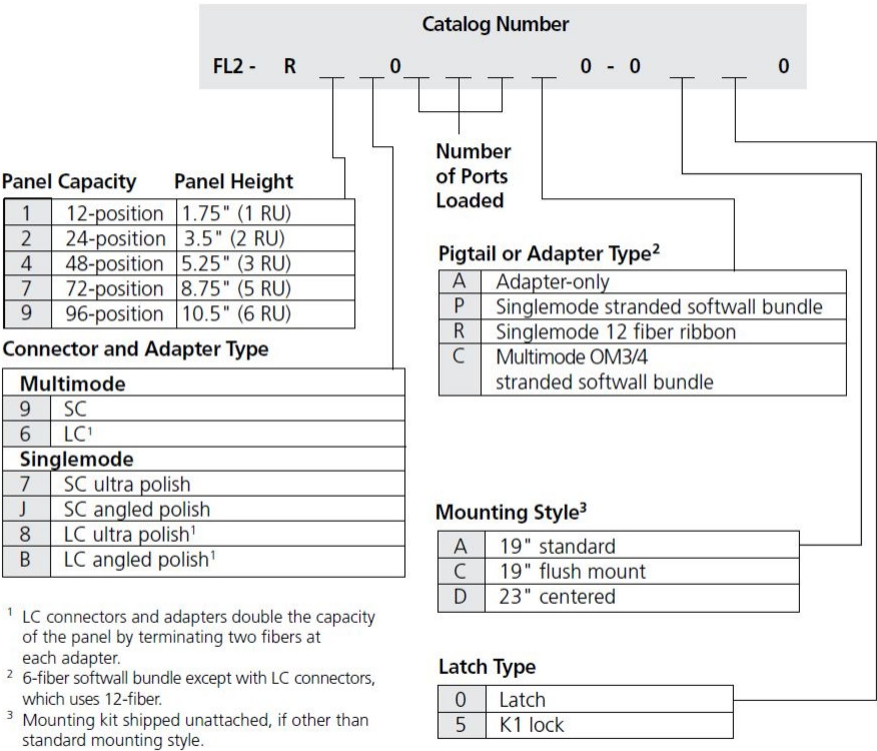

## Material Specifications

Finish	Powder coated
Material Type	Steel

## Optical Specifications

Fiber Mode	Singlemode
------------	------------

## Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

## Regulatory Compliance/Certifications

# FL2-R170012A0-0A00

---

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

