

# FL2-R190006A0-0C00



FL2000 Fiber Termination Panel, 6 SC/UPC, multimode, 1RU, 19 in, putty white

## Product Classification

Regional Availability	Latin America   North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

## General Specifications


Functionality	Patching
Adapter Packs Included, quantity	1
Color	Putty white
Growth Configuration	Partially loaded
Interface, front	SC/UPC
Rack Type	EIA 19 in
Rack Units	1
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	6

## Dimensions

Height	44.45 mm   1.75 in
Width	482.6 mm   19 in
Depth	256.54 mm   10.1 in

## Ordering Tree

# FL2-R1900006A0-0C00

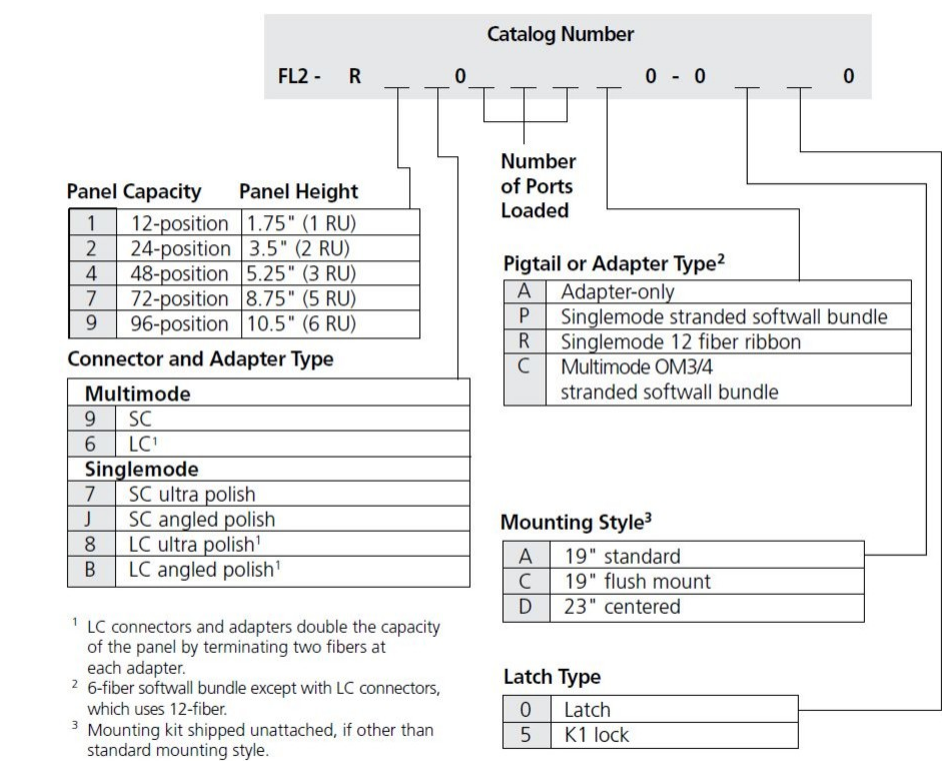

## Material Specifications

Finish	Powder coated
Material Type	Steel

## Optical Specifications

Fiber Mode	Multimode
------------	-----------

## Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

## Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

## Regulatory Compliance/Certifications

# FL2-R190006A0-0C00

---

**Agency**

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS



**Classification**

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)

Compliant

Compliant/Exempted