


FL2-R770072R0-0D00

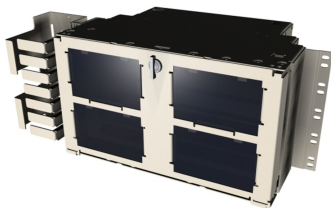

FL2000 Fiber Termination Panel, 72 SC/UPC, singlemode, 5RU, 23 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications


Functionality	Patching
Adapter Packs Included, quantity	12
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Rack Type	EIA 23 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	72

Dimensions

Height	222.25 mm 8.75 in
Width	584.2 mm 23 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-R770072R0-0D00

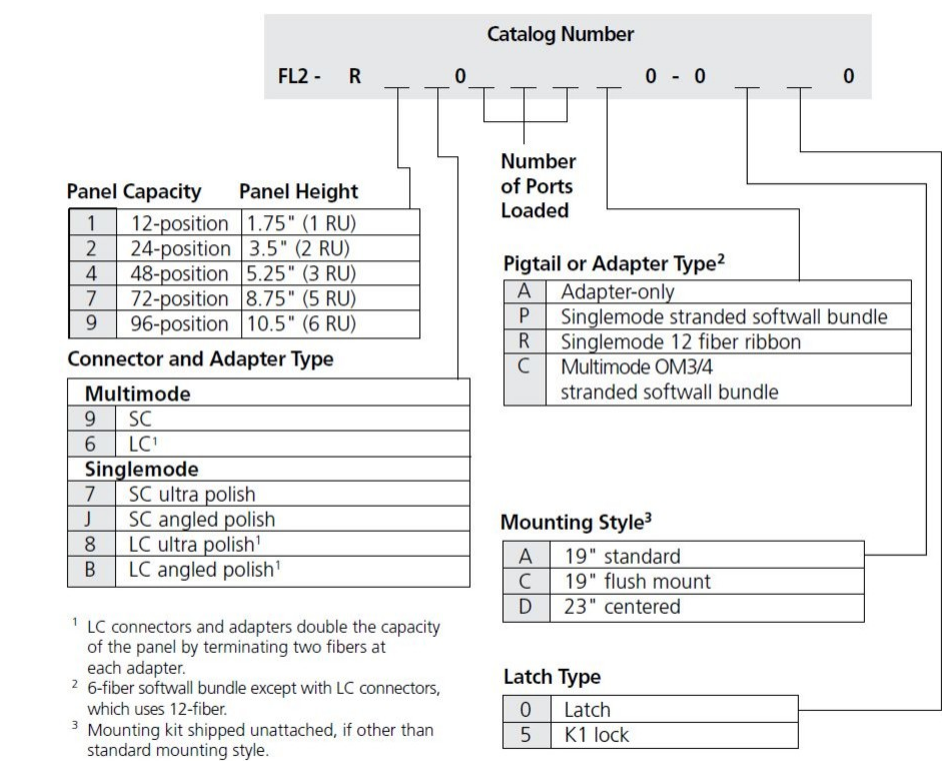

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

FL2-R770072R0-0D00

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS



Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant