

# FMT-DBS000000-S00P



FMT Fiber Storage Panel, with sliding tray, with storage spools, 1RU, 23 in, putty white

## Product Classification

Regional Availability	Latin America   North America
Portfolio	CommScope®
Product Type	Fiber storage panel
Product Series	FMT

## General Specifications


Functionality	Slack storage
Body Style	Symmetrical
Color	Black + Putty white (front)
Growth Configuration	Unloaded
Interface, front	Unloaded
Rack Type	EIA 19 in   EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Splicing Capacity, maximum	0
Total Ports, quantity	0

## Dimensions

Height	44.45 mm   1.75 in
Width	482.6 mm   19 in
Depth	279.91 mm   11.02 in

## Ordering Tree

# FMT-DBS000000-S00P

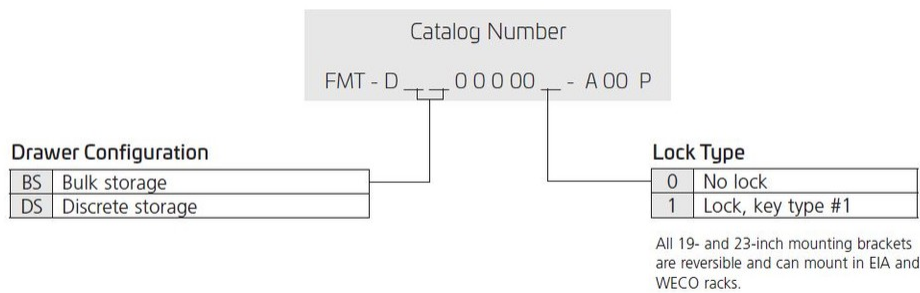

## Material Specifications

Finish	Powder coated
Material Type	Steel

## Packaging and Weights

Packaging quantity	1
--------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="https://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

