

FPX-5FRP07-1441



FPX Fiber Optic Termination/Splice Module, 5RU, 19in, Singlemode, 144 fiber, SC/UPC Connector, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FPX

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	12
Body Style	Symmetrical
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Growth Configuration	Fully loaded
Interface, front	SC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	5
Shelf Movement	Sliding
Splicing Type	Bare fusion
Total Fibers, quantity	144
Total Ports, quantity	144

Dimensions

Height	222.25 mm 8.75 in
Width	482.6 mm 19 in
Depth	304.8 mm 12 in

FPX-5FRP07-1441

Ordering Tree

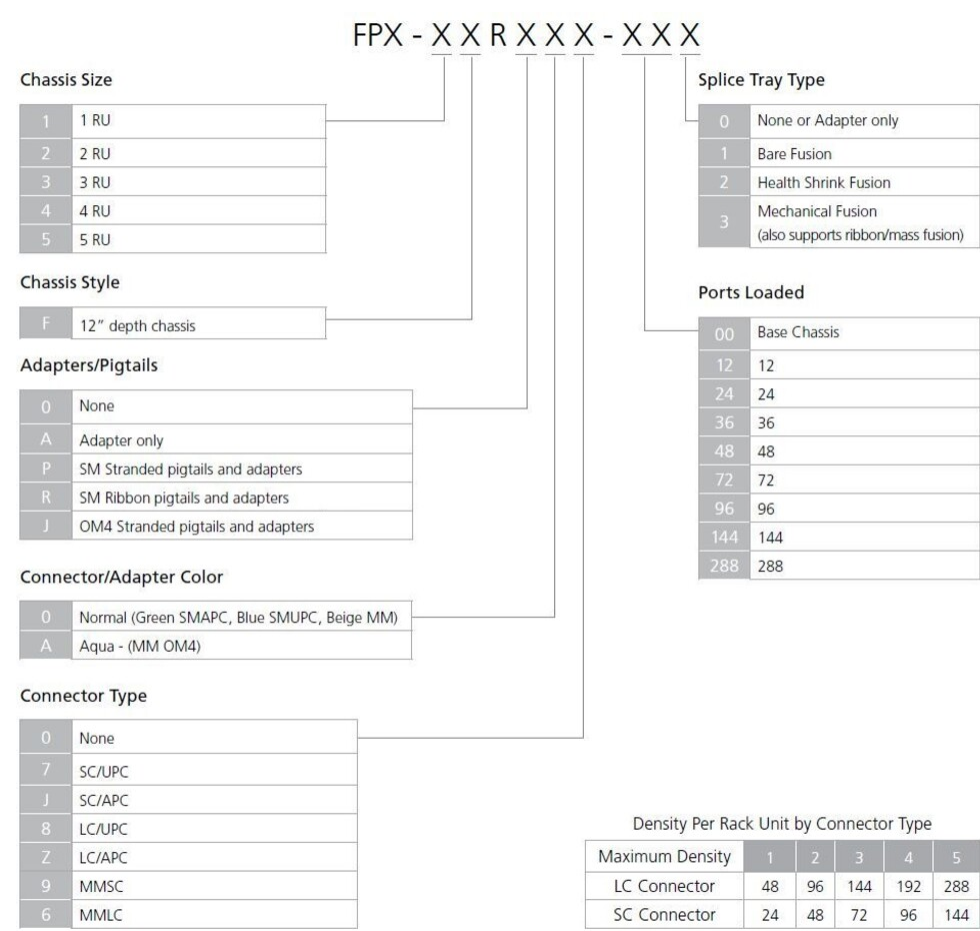

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +85 °C (-40 °F to +185 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

FPX-5FRP07-1441

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

