

# TFP-12APLC4

---

TFP Fiber Optic Adapter Pack, 12-fiber, Multimode, SC, duplex, left, aqua

## Product Classification

<b>Regional Availability</b>	Asia   Latin America   North America
<b>Portfolio</b>	NETCONNECT®
<b>Product Type</b>	Fiber adapter pack
<b>Product Series</b>	TFP

## General Specifications


<b>Application</b>	For use with TFP panels
<b>Adapter Color</b>	Aqua
<b>Adapters, quantity, front</b>	6
<b>Body Style</b>	Duplex   Left orientation
<b>Color, front</b>	Black
<b>Interface</b>	SC/UPC
<b>Total Ports, quantity, front</b>	12

## Dimensions

<b>Height</b>	33.53 mm   1.32 in
<b>Width</b>	176.02 mm   6.93 in

## Ordering Tree

# TFP-12APLC4

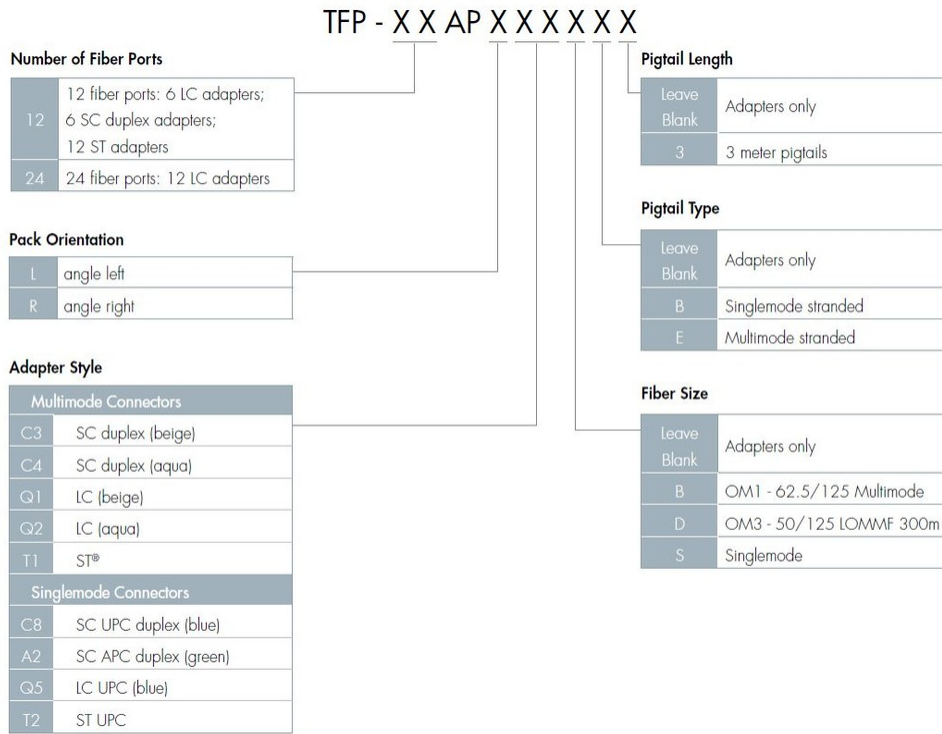

## Optical Specifications

**Fiber Mode** Multimode

## Environmental Specifications

**Operating Temperature** 0 °C to +70 °C (+32 °F to +158 °F)

**Storage Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

## Packaging and Weights

**Packaging quantity** 1

**Packaging Type** Bag | Carton

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant/Exempted

# TFP-12APLC4

---

