

TFP-12APLC4

TFP Fiber Optic Adapter Pack, 12-fiber, Multimode, SC, duplex, left, aqua

Product Classification

Regional Availability	Asia Latin America North America
Portfolio	NETCONNECT®
Product Type	Fiber adapter pack
Product Series	TFP

General Specifications


Application	For use with TFP panels
Adapter Color	Aqua
Adapters, quantity, front	6
Body Style	Duplex Left orientation
Color, front	Black
Interface	SC/UPC
Total Ports, quantity, front	12

Dimensions

Height	33.53 mm 1.32 in
Width	176.02 mm 6.93 in

Ordering Tree

TFP-12APLC4

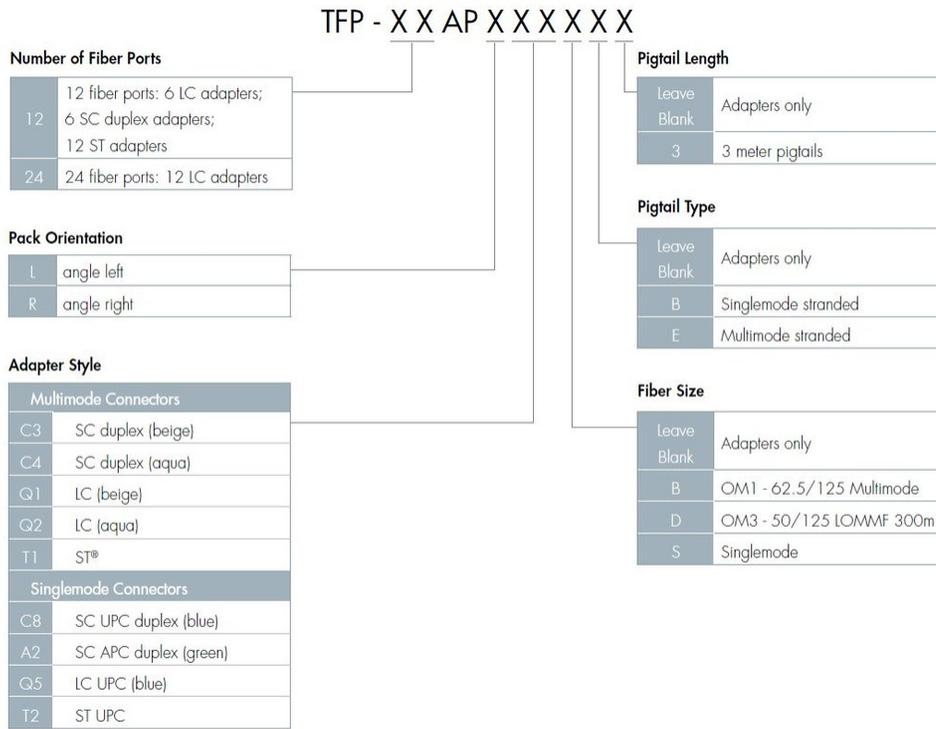

Optical Specifications

Fiber Mode Multimode

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)

Storage Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Packaging and Weights

Packaging quantity 1

Packaging Type Bag | Carton

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

TFP-12APLC4

