

2055109



Fiber Optic Patch Cord, Duplex, Multimode, LC/UPC to SC/UPC, Aqua

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Series	205

General Specifications


Connector A, quantity	2
Color, boot A	Blue
Color, connector A	Beige
Connector B, quantity	2
Color, boot B	Blue
Color, connector B	Beige
Interface, Connector A	LC/UPC
Interface, Connector B	SC/UPC
Jacket Color	Aqua
Polarity	Pairs, flipped

Dimensions

Cable Assembly Length Range (m)	1 – 100
Diameter Over Jacket	1.8 mm 0.071 in

Ordering Tree

2055109

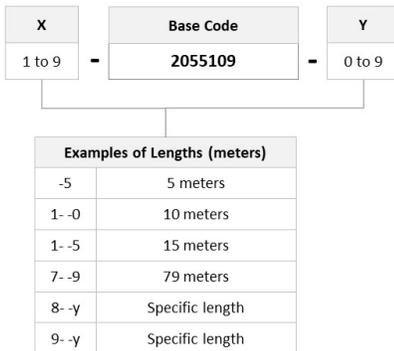

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®
Insertion Loss, maximum, connector A	0.15 dB
Insertion Loss, maximum, connector B	0.15 dB
Return Loss, minimum, connector A	35 dB
Return Loss, minimum, connector B	35 dB

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Low Smoke Zero Halogen (LSZH)
Qualification Standards	IEC 60332-1 IEC 60332-3 IEC 60754 IEC 61034

Packaging and Weights

Packaging quantity	1
---------------------------	---