

Fiber Optic Patch Cord, OM3, LC/UPC to LC/UPC duplex, 1.8 mm LSZH & OFNR, Aqua

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   China   India |
| <b>Portfolio</b>             | CommScope®                                   |
| <b>Product Type</b>          | Fiber patch cord, duplex                     |

## General Specifications

|                               |                |
|-------------------------------|----------------|
| <b>Color, boot A</b>          | Aqua           |
| <b>Color, boot B</b>          | Aqua           |
| <b>Color, connector A</b>     | Beige          |
| <b>Color, connector B</b>     | Beige          |
| <b>Connector A, quantity</b>  | 2              |
| <b>Connector B, quantity</b>  | 2              |
| <b>Interface, Connector A</b> | LC/UPC         |
| <b>Interface, Connector B</b> | LC/UPC         |
| <b>Jacket Color</b>           | Aqua           |
| <b>Polarity</b>               | Pairs, flipped |
| <b>Total Fibers, quantity</b> | 2              |


## Dimensions

|                             |                   |
|-----------------------------|-------------------|
| <b>Diameter Over Jacket</b> | 1.8 mm   0.071 in |
|-----------------------------|-------------------|

## Ordering Tree

# 2105027

---

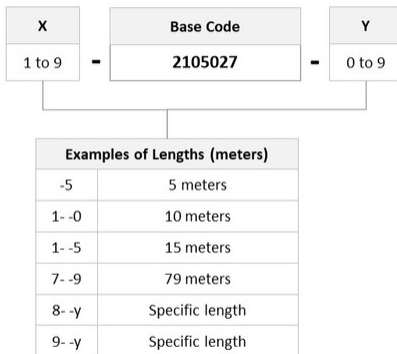

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 °

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM3, LazrSPEED®

**Insertion Loss, maximum** 0.3 dB

**Return Loss, minimum** 20 dB

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

**Qualification Standards** IEC 60332-1 | IEC 60332-3 | IEC 60754 | IEC 61034

## Packaging and Weights

**Packaging quantity** 1