

2105028



Fiber Optic Patch Cord, Single-mode, LC/UPC to LC/UPC duplex, 1.8 mm LSZH & OFNR, Yellow

Product Classification

Regional Availability	Asia Australia/New Zealand China India
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex

General Specifications


Color, boot A	Blue
Color, boot B	Blue
Color, connector A	Blue
Color, connector B	Blue
Connector A, quantity	2
Connector B, quantity	2
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Polarity	Pairs, flipped
Total Fibers, quantity	2

Dimensions

Diameter Over Jacket	1.8 mm 0.071 in
-----------------------------	-------------------

Ordering Tree

2105028

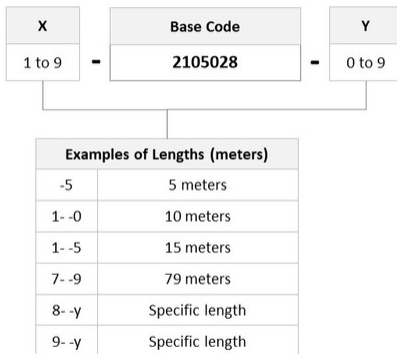

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 °

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2, TeraSPEED®
Insertion Loss, maximum 0.3 dB
Return Loss, minimum 50 dB

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Dual Rated LSZH/Riser
Qualification Standards IEC 60332-1 | IEC 60332-3 | IEC 60754 | IEC 61034

Packaging and Weights

Packaging quantity 1