


# F3ZMPMXAK

Base Product

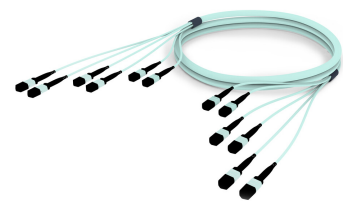

OM3 MPO (Unpinned) to MPO (Pinned), InstaPATCH® 360 Pre-terminated Trunk Cable, 72-Fiber, Low Smoke Zero Halogen B2ca

**OBSOLETE**

This product was discontinued on: October 7, 2024

Replaced By:

U3XMPPMXCK

Ultra Low Loss ULL LazrSPEED® 550 MPO(Unpinned) to MPO(Pinned) Pre-terminated Trunk Cable, MPO12, 72-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration   Not available in the United States or Canada


## General Specifications

Color, boot A	Black
Color, connector A	Aqua
Color, boot B	Black
Color, connector B	Aqua
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-12/UPC Female
Interface, Connector B	MPO-12/UPC Male
Jacket Color	Aqua
Polarity	Method B (LL)
Fibers per Subunit, quantity	12

# F3ZMPMXAK

Total Fibers, quantity	72
Dimensions	
Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

## Ordering Tree

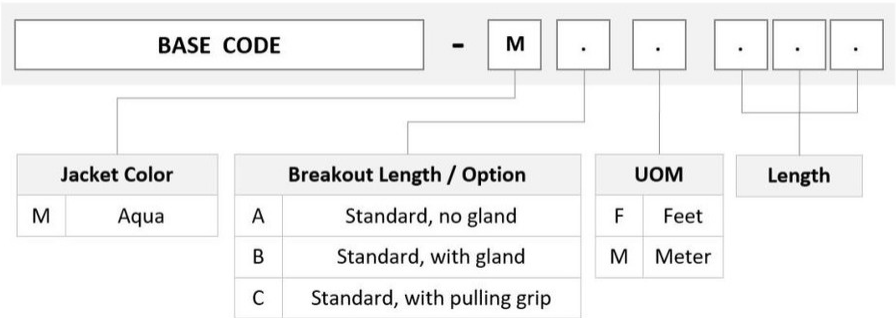

## Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 °   4.40 lb @ 90 °
-----------------------------------	---------------------------------

## Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM3, LazrSPEED®

## Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor   Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>

# F3ZMPMXAK

---

ROHS

UK-ROHS

Compliant/Exempted

Compliant/Exempted



## Included Products

- 760239596  
N-072-MP-5L-F12AQ/B2

860647047

860647054
- -

-
- Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 12 fiber subunits, Multimode OM3, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating

MPO12, LOW LOSS, MALE, OM3/4, AQUA, 3mm

MPO12, LOW LOSS, FEMALE, OM3/4, AQUA, 3mm