


6536880

Base Product

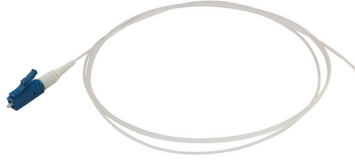

Fiber Optic Pigtail, Singlemode, LC/UPC to Stub, 0.9 mm Semi-Tight, white

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed

General Specifications

Connector A, quantity	1
Color, boot A	Blue
Color, connector A	Blue
Interface, Connector A	LC/UPC
Jacket Color	White
Total Fibers, quantity	1

Dimensions

Diameter Over Jacket	0.9 mm 0.035 in
-----------------------------	-------------------

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	OS2
Insertion Loss, maximum, connector A	0.3 dB
Return Loss, minimum, connector A	45 dB

Environmental Specifications

6536880

Environmental Space

Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity

1

Regulatory Compliance/Certifications

Agency

Classification

ANATEL

Compliant

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

