


F4ZLCLCAG

Base Product

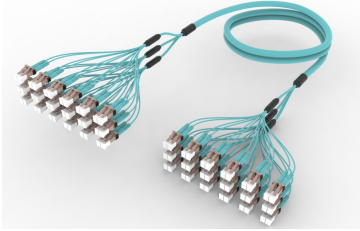

OM3 LC/UPC to LC/UPC 36-Fiber InstaPATCH® 360 Ruggedized Fanout Cable, Low Smoke Zero Halogen

Product Classification

Regional Availability	Europe Middle East/Africa
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration Not available in the United States or Canada

General Specifications


Color, boot A	Aqua
Color, connector A	Beige
Color, boot B	Aqua
Color, connector B	Beige
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Fibers per Subunit, quantity	12
Total Fibers, quantity	36

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	8 – 999

Ordering Tree

F4ZLCLCAG

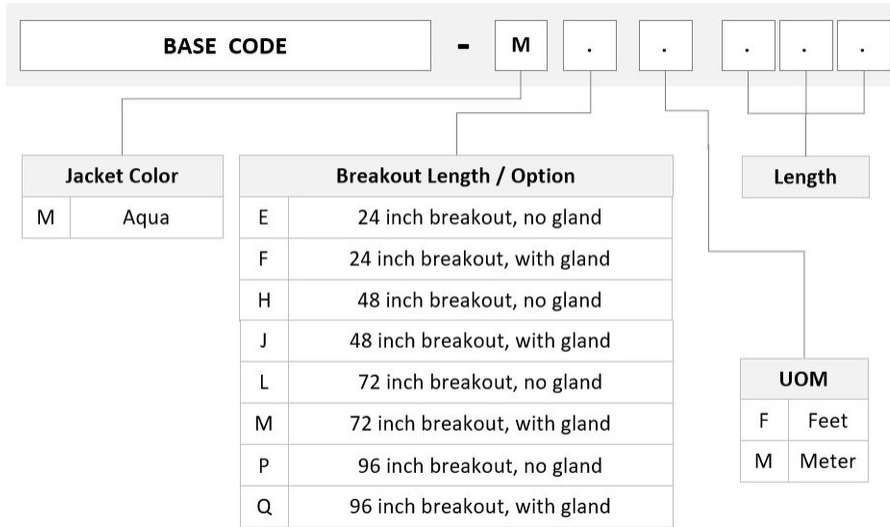

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM3, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant



F4ZLCLCAG

Included Products

- 460125198 – Pre-Radiused LC Connector duplex for 1.6 mm Fiber, multimode
- 760239594 – Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser, 36 fibers, MPO Trunk, 12 fiber subunits, Multimode OM3, Gel-free, Feet jacket marking, Aqua jacket color, B2ca flame rating
- N-036-MP-5I-F12AQ/B2