


FBXLCUC11

Base Product

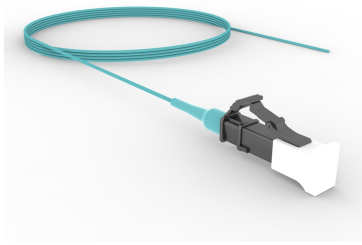

OM4 LC/UPC to Unconnectorized, Fiber Pigtail, 0.9 mm SBJ

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	SYSTIMAX InstaPATCH® 360
Product Series	FBX
Ordering Note	Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Aqua
Color, connector A	Black
Interface, Connector A	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	1
Transmission Standards	TIA/EIA-568-C.3

Dimensions

Cable Assembly Length Range (m)	1 – 20
Cable Assembly Length Range (ft)	1 – 66

Ordering Tree

FBXLCUC11

- 760010603
N-001-RF-5K-F09AQ – Fiber Indoor Cable, LazrSPEED® 0.9 mm Low Smoke Zero Halogen Reinforced Buffered, 1 fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color
- 860657284 – LC/UPC Connector, Multimode, Aqua