


# FLWSASAAD

## Base Product

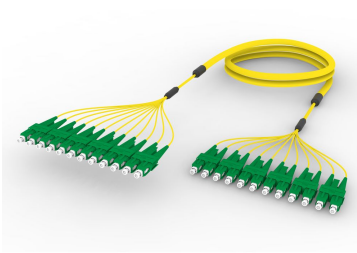

Singlemode SC/APC to SC/APC, InstaPATCH® 360 Ruggedized Fiber Fanout Cable Assembly, 12-Fiber, Plenum

## Product Classification

|                              |  |
|------------------------------|--|
| <b>Regional Availability</b> | Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America                              |
| <b>Portfolio</b>             | CommScope®   |
| <b>Product Type</b>          | Ruggedized fanout  |
| <b>Product Brand</b>         | SYSTIMAX InstaPATCH® 360   |
| <b>Ordering Note</b>         | For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications


|                                     |          |
|-------------------------------------|----------|
| <b>Color, connector A</b>           | Green    |
| <b>Color, connector B</b>           | Green    |
| <b>Construction Type</b>            | Stranded |
| <b>Furcation Color</b>              | Yellow   |
| <b>Interface, Connector A</b>       | SC/APC   |
| <b>Interface, Connector B</b>       | SC/APC   |
| <b>Fibers per Subunit, quantity</b> | 12       |
| <b>Total Fibers, quantity</b>       | 12       |

## Dimensions

|   |         |
|---|---------|
| <b>Cable Assembly Length Range (m)</b>  | 3 – 999 |
| <b>Cable Assembly Length Range (ft)</b> | 8 – 999 |

## Ordering Tree

# FLWSASAAD

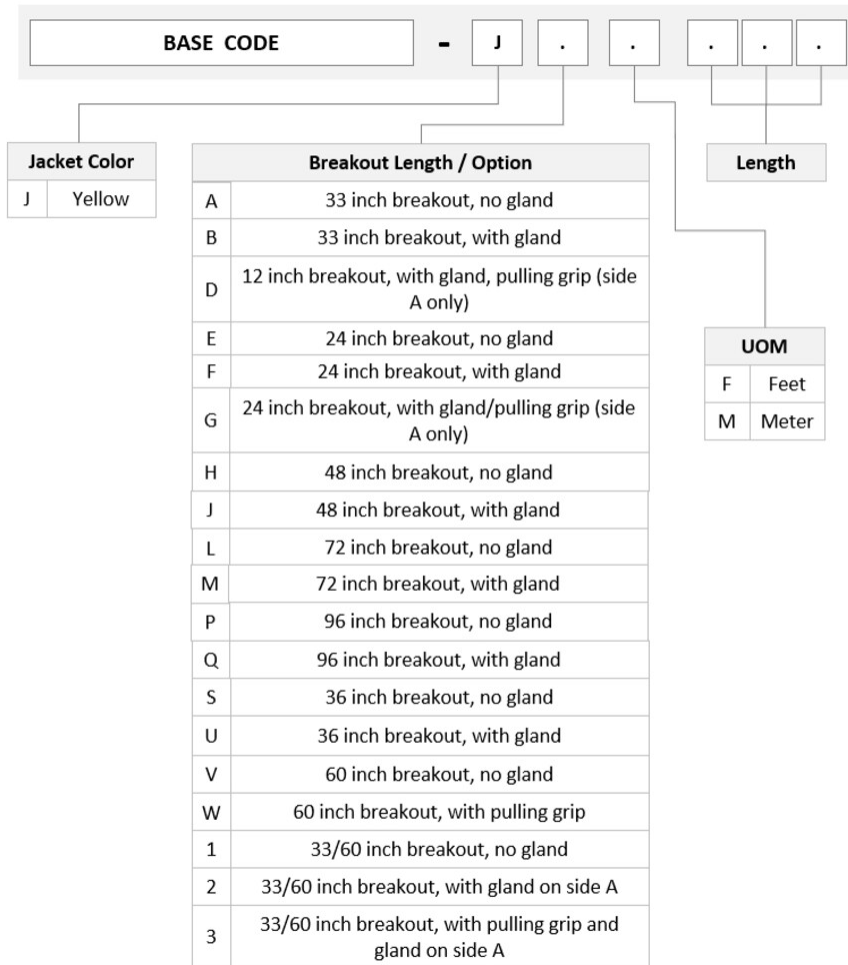

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.652.D | G.657.A1, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Indoor | Plenum

## Regulatory Compliance/Certifications

# FLWSASAAD

---

**Agency**

ISO 9001:2015

**Classification**

Designed, manufactured and/or distributed under this quality management system

## Included Products

- 760237963  
P-012-MP-8G1-F12YL - Fiber indoor cable, Plenum for MPO Trunks, 12 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
- 860648957 - SC/APC Connector, Singlemode, Green