


FSWLCLCW6

Base Product

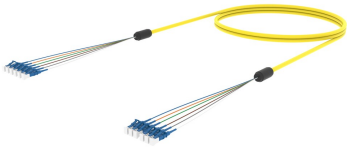

TeraSPEED® LC/UPC to LC/UPC, Distribution Cable, 6-Fiber, Plenum

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications


Color, connector A	Blue
Color, connector B	Blue
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (m)	3 – 305
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

FSWLCLCW6

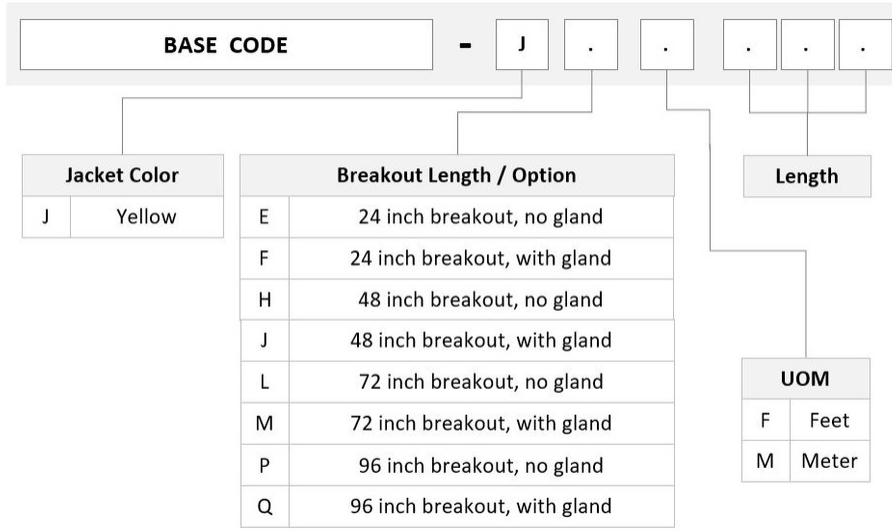

Mechanical Specifications

Cable Retention Strength, maximum 0.50 lb @ 0° | 0.50 lb @ 90°

Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A1, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

ISO 9001:2015

REACH-SVHC

ROHS

UK-ROHS

Classification

Below maximum concentration value

Designed, manufactured and/or distributed under this quality management system

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

Compliant



FSWLCLCW6

Included Products

- 760004333
P-006-DS-8W-FSUYL - Fiber indoor cable, TeraSPEED® Plenum Distribution, 6 fiber single-unit, Singlemode G.652.D and G.657.A1, Feet jacket marking, Yellow jacket color
- 860637428 - LC/UPC Connector, Singlemode, Blue