


U3GMPUCAK

Base Product

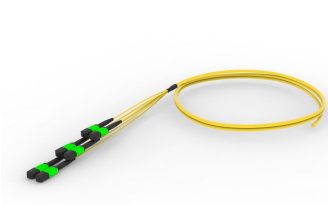

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to Unconnectorized, Fiber Trunk Cable Assembly, 72-Fiber, CPR Class B2ca, Low Smoke Zero Halogen/Riser

OBSOLETE

This product was discontinued on: April 30, 2024

Replaced By:

U3GMPUCCK Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to Unconnectorized, Fiber Trunk Cable Assembly, 72-Fiber, CPR Class B2ca,Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability	Europe
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, boot A	Black
Color, connector A	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	Unterminated
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)

UBGMPUCAK

Fibers per Subunit, quantity	12
Total Fibers, quantity	72
Dimensions	
Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

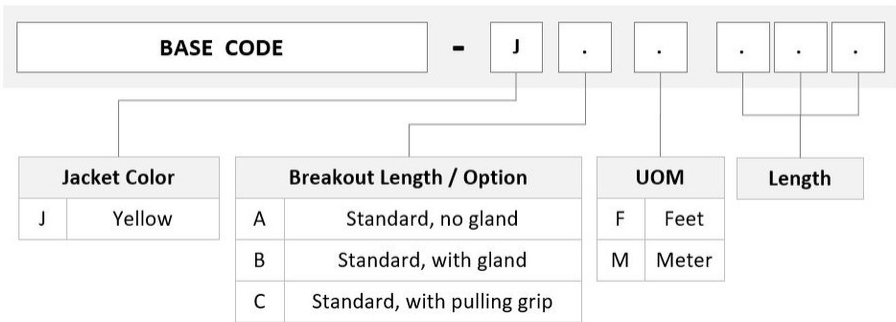

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
EN50575 CPR Cable EuroClass Fire Performance	B2ca
Environmental Space	Indoor Low Smoke Zero Halogen (LSZH)

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CENELEC	EN 50575 compliant, Declaration of Performance (DoP) available
CHINA-ROHS	Above maximum concentration value

U3GMPUCAK

ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760239622	–	Fiber Indoor Cable, Low Smoke Zero Halogen Riser MPO Trunk Cable, 72 fiber, gel-free,
N-072-MP-8G1-F12YL/B2		singlemode G.657.A2/B2, feet jacket marking, yellow cable jacket color, B2ca Flame Rating
860638318	–	MP012, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm