


# U3XQXQXQL

## Base Product

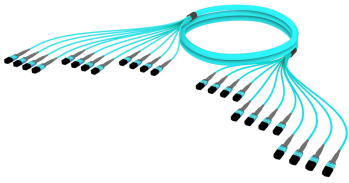

Ultra Low Loss (ULL) OM4, MPO8 QSFP Pinned to MPO8 QSFP Pinned, Fiber Trunk Cable Assembly, 96-Fiber, Low Smoke Zero Halogen

This product will be discontinued on: April 30, 2024

### Replaced By:

U3XQXQXTL

Ultra Low Loss (ULL) OM4 MPO8 (Pinned) to MPO8 (Pinned), Fiber Trunk Cable Assembly, 96-Fiber, LZSH B2ca

## Product Classification

<b>Regional Availability</b>	Europe
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	Not available in the United States or Canada

## General Specifications

<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Aqua
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Aqua
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Aqua
<b>Interface, Connector A</b>	MPO-08/UPC Male
<b>Interface Feature, connector A</b>	QSFP configuration
<b>Interface, Connector B</b>	MPO-08/UPC Male
<b>Interface Feature, connector B</b>	QSFP configuration
<b>Jacket Color</b>	Aqua
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8


# U3XQXQXQL

**Total Fibers, quantity** 96

## Dimensions

**Breakout Length** 33 in  
**Cable Assembly Length Range (m)** 3 – 999  
**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

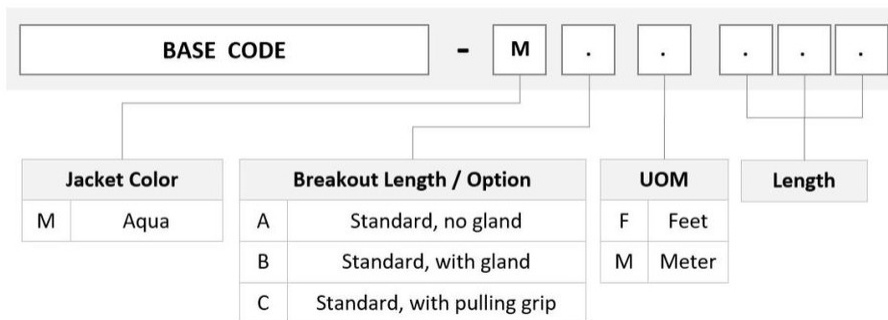

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

**Fiber Mode** Multimode  
**Fiber Type** OM4, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)  
**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted

# U3XQXQXQL

---

UK-ROHS

Compliant/Exempted



## Included Products

- 760239603  
N-096-MP-5K-F12AQ/B2
  - 860633308
- Fiber indoor cable, LazrSPEED®, Low Smoke Zero Halogen Riser MPO Trunk, 96 fiber, 12 fiber subunits, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color, B2ca Flame rating
  - MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m