


# U4GSASACD

Base Product

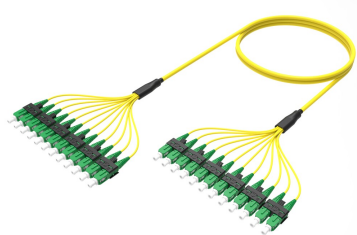

Ultra Low Loss ULL TeraSPEED® SC/APC to SC/APC Ruggedized fanout Cable, 12-Fiber, LSZH, 12 fiber PmP 2.0 mm /B2ca

## Product Classification

|                       |  |
|-----------------------|--|
| Regional Availability | Asia   Australia/New Zealand   Europe   Latin America   Middle East/Africa   North America   |
| Portfolio             | CommScope®   |
| Product Type          | Ruggedized fanout  |
| Product Brand         | SYSTIMAX ULL   |
| Ordering Note         | For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration |

## General Specifications

|                                |          |
|--------------------------------|----------|
| Color, boot A                  | Green    |
| Color, connector A             | Green    |
| Color, boot B                  | Green    |
| Color, connector B             | Green    |
| Construction Type              | Stranded |
| Furcation Color                | Yellow   |
| Interface, Connector A         | SC/APC   |
| Interface Feature, connector A | ULL      |
| Interface, Connector B         | SC/APC   |
| Interface Feature, connector B | ULL      |
| Jacket Color                   | Yellow   |
| Fibers per Subunit, quantity   | 12       |
| Total Fibers, quantity         | 12       |

## Dimensions

|                                 |         |
|---------------------------------|---------|
| Cable Assembly Length Range (m) | 3 – 999 |
|---------------------------------|---------|

# U4GSASACD

---

**Cable Assembly Length Range (ft)** 8 – 999

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**EN50575 CPR Cable EuroClass Fire Performance** B2ca

**Environmental Space** Indoor | Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

| Agency        | Classification   |
|---------------|--|
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |