


UBXLCUC11

Base Product

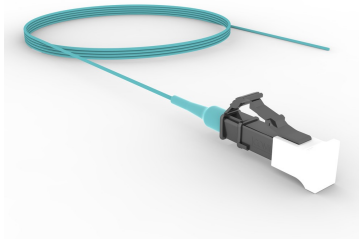

Ultra Low Loss (ULL) LazrSPEED® 550 LC/UPC to Unconnectorized, Fiber Pigtail, 0.9 mm Riser - SBJ

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber pigtail, unjacketed |
| Product Brand | SYSTIMAX ULL |
| Product Series | UBX |
| Ordering Note | Minimum length may vary based on cable configuration |

General Specifications

| | |
|-------------------------------|--------|
| Color, boot A | Aqua |
| Color, connector A | Black |
| Interface, Connector A | LC/UPC |
| Jacket Color | Aqua |
| Total Fibers, quantity | 1 |

Dimensions

| | |
|---|---------|
| Cable Assembly Length Range (m) | 1 – 61 |
| Cable Assembly Length Range (ft) | 2 – 200 |

Ordering Tree

UBXLCUC11



Mechanical Specifications

Cable Retention Strength, maximum 2.00 lb @ 90 ° | 5.00 lb @ 0 °

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Low Smoke Zero Halogen (LSZH)

Packaging and Weights

Packaging quantity 2

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

760010603 – Fiber Indoor Cable, LazrSPEED® 0.9 mm Low Smoke Zero Halogen Reinforced Buffered, 1
N-001-RF-5K-F09AQ fiber, Multimode OM4, Gel-free, Feet jacket marking, Aqua jacket color

UBXLCUC11

860657287

– LC/PC Connector, Multimode, Aqua