


UFGLCLC42

Base Product

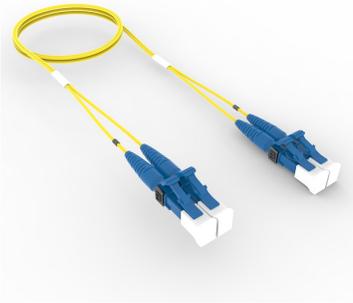

Ultra Low Loss Singlemode, LC/UPC to LC/UPC, Fiber Patch Cord, 1.6 mm Duplex, Low Smoke Zero Halogen

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Fiber patch cord, duplex
Product Brand	SYSTIMAX ULL
Product Series	UFG
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Blue
Color, connector A	Blue
Color, boot B	Blue
Color, connector B	Blue
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Polarity	Pairs, flipped
Total Fibers, quantity	2
Transmission Standards	TIA/EIA-568-C.3

Dimensions


Cable Assembly Length Range (m)	1 – 999
Cable Assembly Length Range (ft)	1 – 999

UFGLCLC42

Diameter Over Jacket

1.6 mm | 0.063 in

Ordering Tree

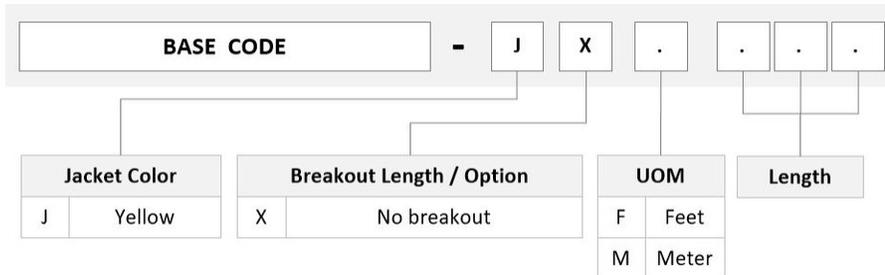

Mechanical Specifications

Cable Retention Strength, maximum

11.24 lb @ 0 ° | 4.40 lb @ 90 °

Optical Specifications

Fiber Mode

Singlemode

Fiber Type

G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature

-10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space

Dual Rated LSZH/Riser

Qualification Standards

GR-326 CORE

Packaging and Weights

Packaging quantity

1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted



UFGLCLC42

Included Products

- 760238070 – 1.6mm Low Smoke Zero Halogen Riser Zipcord Cable
- N-002-ZC-8G-F16YL/E
- 860655464 – LC/UPC Connector, Singlemode, Blue