


# UGGMPMXRP

---

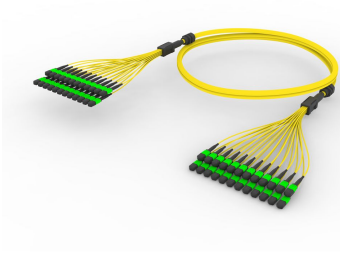

Ultra Low Loss (ULL) Singlemode MPO12 (Unpinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 288-Fiber, Rollable Ribbon Central Tube, Plenum

## Product Classification

<b>Regional Availability</b>	Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Black
<b>Color, boot B</b>	Black
<b>Color, connector A</b>	Green
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Rollable ribbon
<b>Fibers per Subunit, quantity</b>	12
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-12/APC Female
<b>Interface, Connector B</b>	MPO-12/APC Male
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Total Fibers, quantity</b>	288


## Dimensions

<b>Breakout Length</b>	33 in
------------------------	-------

# UGGMPMXRP

<b>Cable Assembly Length Range (m)</b>	3 – 999
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

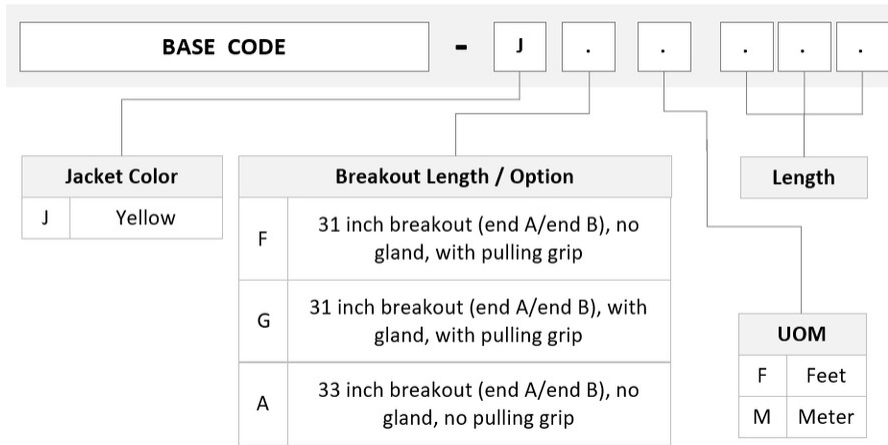

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0°   4.40 lb @ 90°
--	-------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Plenum

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



## Included Products

760239140	-	Fiber indoor cable, Plenum All-Dielectric Central Tube Rollable Ribbon, 288 fiber, Singlemode G.
-----------	---	--

# UGGMPMXRP

---

P-288-CN-RR-F12YL/8G/99E

657.A2/B2, Feet jacket marking, Yellow jacket color

860638317

– MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm

860638318

– MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm