


# UGGMXMXRP

Base Product

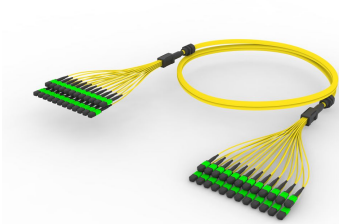

Ultra Low Loss (ULL) Singlemode MPO12 (Pinned) to MPO12 (Pinned), Fiber Trunk Cable Assembly, 288-Fiber, Rollable Ribbon Central Tube, Plenum

## Product Classification

Regional Availability	Latin America   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface, Connector B	MPO-12/APC Male
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	288


## Dimensions

Cable Assembly Length Range (m)	3 – 999
---------------------------------	---------

# UGGMXXMRP

Cable Assembly Length Range (ft) 10 – 999

## Ordering Tree

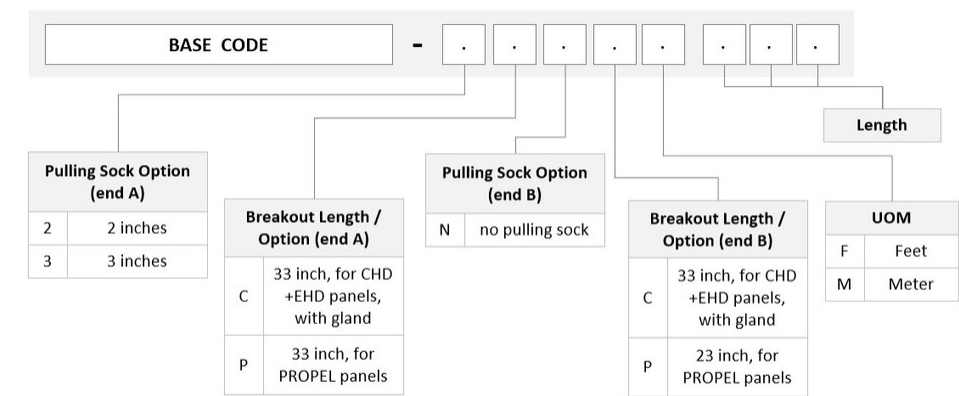

## Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

Fiber Mode Singlemode

Fiber Type G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Plenum

## Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## Included Products

760239140	–	Fiber indoor cable, Plenum All-Dielectric Central Tube Rollable Ribbon, 288 fiber, Singlemode G.
P-288-CN-RR-F12YL/8G/99E		657.A2, Feet jacket marking, Yellow jacket color
860638317	–	MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm