


Base Product

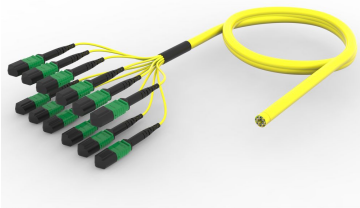

Ultra Low Loss (ULL) Singlemode, MPO12 Pinned to Unconnectorized, Fiber Trunk Cable Assembly, 144-Fiber, Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability	Asia   Australia/New Zealand   China   Europe   India   Latin America   Middle East/Africa   North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Male
Interface, Connector B	Unterminated
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	144


Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999

# UJGMXUCAM

Cable Assembly Length Range (ft) 10 – 999

## Ordering Tree

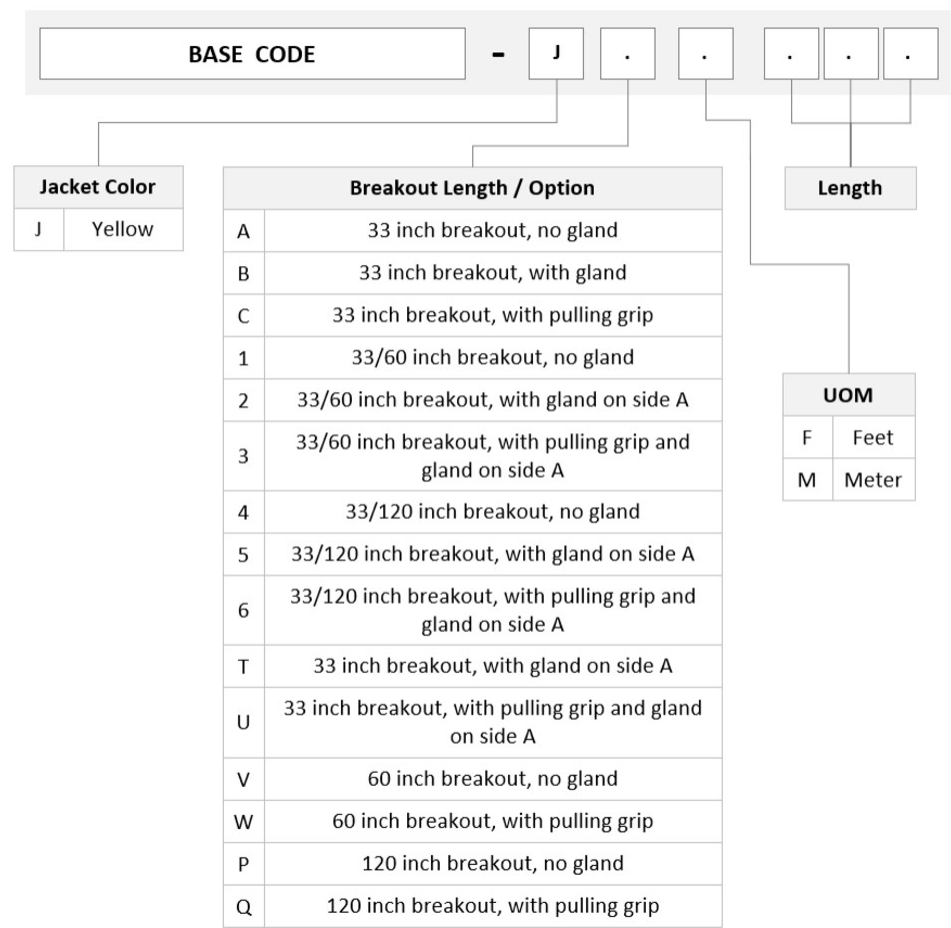

## Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0 ° | 4.40 lb @ 90 °

## Optical Specifications

Fiber Mode Singlemode  
Fiber Type G.657.A2, TeraSPEED®

## Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)  
Environmental Space Dual Rated LSZH/Riser | Indoor

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



Included Products

760237978 N-144-MP-8G1-F12YL/D	-	Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 144 fiber multi-unit with 12 fiber subunits, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca flame rating
860638317	-	MPO12, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm